

SPUR GEAR STOCK • 48 & 32 PITCH




AGMA 7

14-1/2° AND 20° PRESSURE ANGLE

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

➤ MATERIAL:
Steel

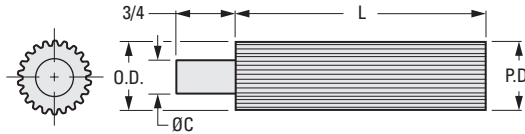

INCH COMPONENT		No. of Teeth	P.D.	O.D.	C Shank Dia.	L Minimum Usable Length	
14-1/2° Pressure Angle	20° Pressure Angle						
48 Pitch							
A 1C29-N48014	A 1C29-Y48014	14	.292	.333	7/32	3	
A 1C29-N48016	A 1C29-Y48016	16	.333	.375	1/4		
A 1C29-N48020	A 1C29-Y48020	20	.417	.458			
A 1C29-N48022	A 1C29-Y48022	22	.458	.500			
A 1C29-N48026	A 1C29-Y48026	26	.542	.583			
A 1C29-N48030	A 1C29-Y48030	30	.625	.667			
A 1C29-N48032	A 1C29-Y48032	32	.667	.708			3/8
A 1C29-N48040	A 1C29-Y48040	40	.833	.875			
A 1C29-N48044	A 1C29-Y48044	44	.917	.958			
A 1C29-N48048	A 1C29-Y48048	48	1.000	1.042			
A 1C29-N48052	A 1C29-Y48052	52	1.083	1.125			
A 1C29-N48056	A 1C29-Y48056	56	1.167	1.208	1/2		
A 1C29-N48060	A 1C29-Y48060	60	1.250	1.292			
A 1C29-N48064	A 1C29-Y48064	64	1.333	1.375			
A 1C29-N48072	A 1C29-Y48072	72	1.500	1.542			
A 1C29-N48080	A 1C29-Y48080	80	1.667	1.708			
A 1C29-N48096	A 1C29-Y48096	96	2.000	2.042		3/4	
A 1C29-N48100	A 1C29-Y48100	100	2.083	2.125			
A 1C29-N48108	A 1C29-Y48108	108	2.250	2.292			
A 1C29-N48120	A 1C29-Y48120	120	2.500	2.542			
32 Pitch							
A 1C29-N32016	A 1C29-Y32016	16	.500	.563	1/4	3	
A 1C29-N32018	A 1C29-Y32018	18	.563	.625	3/8		
A 1C29-N32020	A 1C29-Y32020	20	.625	.688			
A 1C29-N32022	A 1C29-Y32022	22	.688	.750			
A 1C29-N32024	A 1C29-Y32024	24	.750	.813			
A 1C29-N32032	A 1C29-Y32032	32	1.000	1.063			1/2
A 1C29-N32036	A 1C29-Y32036	36	1.125	1.188			
A 1C29-N32038	A 1C29-Y32038	38	1.188	1.250			
A 1C29-N32040	A 1C29-Y32040	40	1.250	1.313			
A 1C29-N32044	A 1C29-Y32044	44	1.375	1.438			
A 1C29-N32048	A 1C29-Y32048	48	1.500	1.563	3/4		
A 1C29-N32054	A 1C29-Y32054	54	1.688	1.750			
A 1C29-N32060	A 1C29-Y32060	60	1.875	1.938			
A 1C29-N32064	A 1C29-Y32064	64	2.000	2.063			
A 1C29-N32072	A 1C29-Y32072	72	2.250	2.313			
A 1C29-N32080	A 1C29-Y32080	80	2.500	2.563		8	
A 1C29-N32084	A 1C29-Y32084	84	2.625	2.688			
A 1C29-N32096	A 1C29-Y32096	96	3.000	3.063			

- I
- R
- T
- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16