

# MINIATURE ROLLER CHAINS • .1475 PITCH



SINGLE STRAND  
RIVETED

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

➤ **MATERIAL:**

Stainless Steel Type 18-8

➤ **FINISH:**

Clear Passivated

➤ **AVERAGE TENSILE LOAD:**

175 lbf

➤ **SPECIFICATION:**

All lengths include and are supplied with connecting link A 6Y 7-14CHA


➤ **WEIGHT:**

.035 lbs per foot

Sizes not listed are available on special request.



CONNECTING LINK

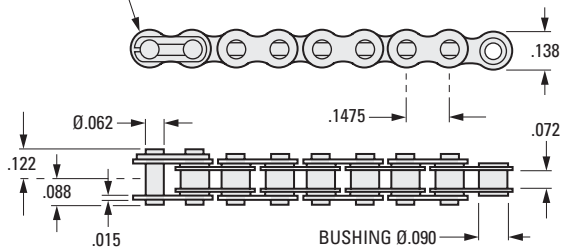

**CONNECTING LINK (SNAP TYPE)**

Catalog Number  
A 6Y 7-14CHA



**BUSHING LINK**

Catalog Number  
A 6Y 7-14BL



**INCH COMPONENT**

Catalog Number	No. of Links	Length
A 6Y 7-M040	40	5.900
A 6Y 7-M050	50	7.375
A 6Y 7-M060	60	8.850
A 6Y 7-M070	70	10.325
A 6Y 7-M080	80	11.800
A 6Y 7-M090	90	13.275
A 6Y 7-M100	100	14.750
A 6Y 7-M110	110	16.225
A 6Y 7-M120	120	17.700
A 6Y 7-M130	130	19.175
A 6Y 7-M140	140	20.650
A 6Y 7-M150	150	22.125
A 6Y 7-M160	160	23.600
A 6Y 7-M170	170	25.075
A 6Y 7-M180	180	26.550
A 6Y 7-M190	190	28.025
A 6Y 7-M200	200	29.500
A 6Y 7-M210	210	30.975
A 6Y 7-M220	220	32.450
A 6Y 7-M230	230	33.925
A 6Y 7-M240	240	35.400

Continuous length available  
Sold by the foot  
A 6Y 7-MC

