





INCH

## Rounthane Belting &amp; Connectors

■ POLYURETHANE

■ NONSLIP

■ 3/16", 1/4" &amp; 5/16" DIAMETER

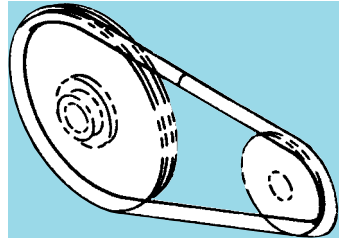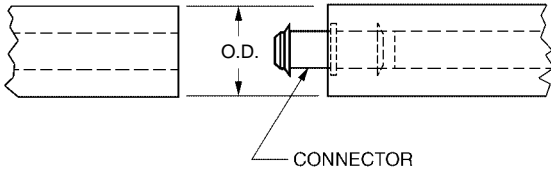

**MATERIAL:** Belting – Polyurethane  
Connectors – Aluminum

**TEMPERATURE RANGE:** -40° F to +150° F

Belting: Priced Per Foot

Connectors: Priced Per 10 Pieces


Belting Catalog Number	O.D.	Recommended Minimum Pulley Dia.	Coefficient of Friction	Connectors Catalog Number
A 6R 1-A06	3/16	1-1/2	0.5 to 0.7	A 6A 1-C06
A 6R 1-A08	1/4	2		A 6A 1-C08
A 6R 1-A10	5/16	2-1/2		A 6A 1-C10

**NOTE:** These belts can be used with Companion Pulleys and Grooved Idlers, having diameters at least 8 times belt diameters. (see Index).

**Installation For Open Drives:** Make belt endless and roll onto pulleys.

**Installation For Closed Drives:** String belt around pulleys, insert connector and roll onto pulleys.

**Table No. 1 – Installed Belt Tension**

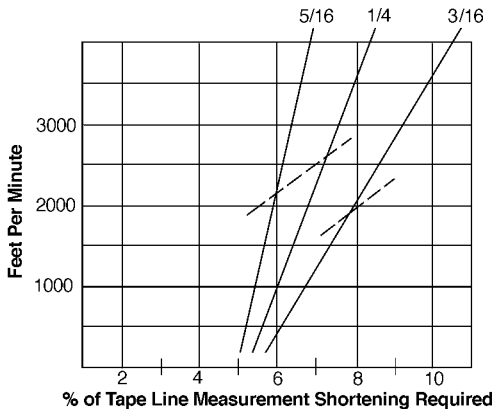

— — — — — Maximum Feet Per Minute for Minimum Pulley Diameter

**Table No. 2 – Maximum HP Capacity**

