





Shafting

■ DRAWN

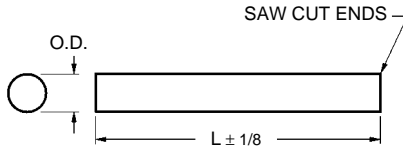

■ SMOOTH FINISH

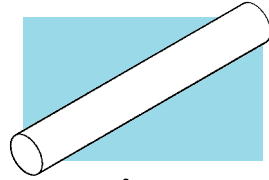

MATERIAL: AISI 12L14 Cold Rolled Steel

Catalog Number	O.D. ± .0005	L Length in.
A 7C 1-0506	.1562	6
A 7C 1-0512		12
A 7C 1-0524		24
A 7C 1-0536		36
A 7C 1-0606	.1875	6
A 7C 1-0612		12
A 7C 1-0624		24
A 7C 1-0636		36
A 7C 1-0806	.2500	6
A 7C 1-0812		12
A 7C 1-0824		24
A 7C 1-0836		36
A 7C 1-1006	.3125	6
A 7C 1-1012		12



Catalog Number	O.D. ± .0005	L Length in.
A 7C 1-1024	.3125	24
A 7C 1-1036		36
A 7C 1-1206	.3750	6
A 7C 1-1212		12
A 7C 1-1224		24
A 7C 1-1236		36
A 7C 1-1406	.4375	6
A 7C 1-1412		12
A 7C 1-1424		24
A 7C 1-1436		36
A 7C 1-1606	.5000	6
A 7C 1-1612		12
A 7C 1-1624		24
A 7C 1-1636		36

Other lengths available on special order.



Drill Rods

■ PRECISION

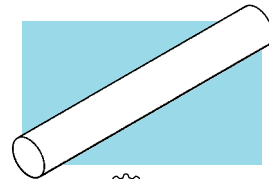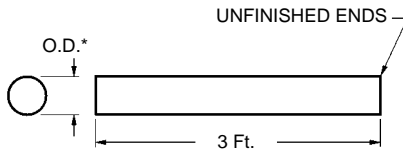

Sold in 3 Ft. Lengths Only.

Catalog Number	O.D.*
A 7Q 1-04	1/8
A 7Q 1-05	5/32
A 7Q 1-06	3/16
A 7Q 1-08	1/4
A 7Q 1-09	9/32
A 7Q 1-10	5/16
A 7Q 1-11	11/32

Catalog Number	O.D.*
A 7Q 1-12	3/8
A 7Q 1-14	7/16
A 7Q 1-16	1/2
A 7Q 1-20	5/8
A 7Q 1-24	3/4
A 7Q 1-28	7/8
A 7Q 1-32	1

MATERIAL: Tool Steel – AISI 1045
FINISH: Ground

Oil Hardening Hi-Quality type of tool steel suitable for punches, dies & high-strength machined parts.

*O.D. tolerance:
from .125 to .499 is ± .0005,
from .500 to 1" is ± .001.