

# MOLDED UNIVERSAL JOINTS • TELESCOPING



WITH BRASS SLIDE EXTENSION  
ELECTRICALLY INSULATING

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM



**> MATERIAL:**

- Body - Molded Acetal
- Spider & Insert - Nickel Plated Brass
- Tube - Brass


**> MAX. OPERATING TEMPERATURE:**

180°F

**> SPECIFICATIONS:**

- Max. Angular Displacement: 90°
- Max. Recommended Extension: D/2

Shorter or longer lengths available on special order.

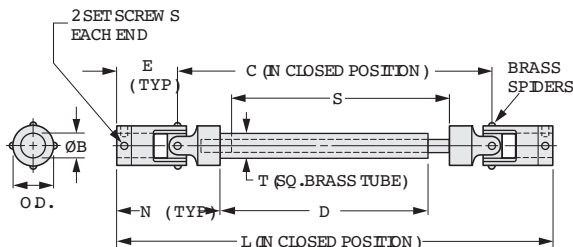

I

R

T

1

2

3

4

5

6

7

8

9

10

11

12

13

14

15

16

**INCH COMPONENT**

Catalog Number	O.D.	B Bore +.001 -.000	Bore Depth (Typ)	E	F	N
A 5Z 8-SEB204	1/4	*1/8	.39	17/32	.27	29/32
A 5Z 8-SEB304	3/8		.52	3/4	.41	1-5/16
A 5Z 8-SEB306	1/2	3/16	.63	29/32	.54	1-39/64
A 5Z 8-SEB406		1/4				
A 5Z 8-SEB408		1/4				
A 5Z 8-SEB508	5/8	5/16	.86	1-21/64	.68	2-3/8
A 5Z 8-SEB510		3/8				
A 5Z 8-SEB512		3/8				

\* One set screw each end.

Catalog Number (Ref.)	Length Closed		D	S	T Square	Set Screw
	L	C				
A 5Z 8-SEB204	3-1/4	2-3/16	1-7/16	1-19/32	1/8	#4-40
A 5Z 8-SEB304	4-7/16	2-15/16	1-13/16	2-3/32	5/32	
A 5Z 8-SEB306						
A 5Z 8-SEB406	6	4-3/16	2-25/32	3-3/32	3/16	#6-32
A 5Z 8-SEB408						
A 5Z 8-SEB508						
A 5Z 8-SEB510	8	5-11/32	3-1/4	3-25/32	1/4	#8-32
A 5Z 8-SEB512						

**NOTE:** Total open length = L (Closed) + D/2 (Max).