
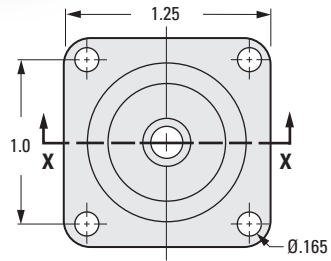


FOR LOADS OF 4 TO 20 lbf



PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

> MATERIAL:


Isolator - Natural Rubber
Base - Steel or Aluminum

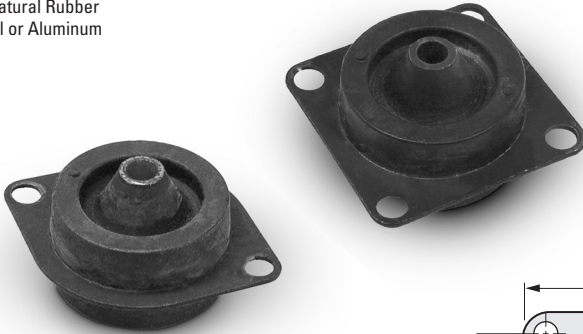



LOAD/DEFLECTION GRAPH
 Maximum Recommended
 Static Load/Deflection

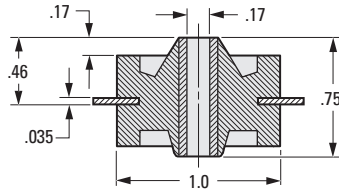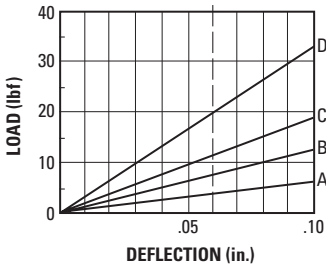

SECTION X-X

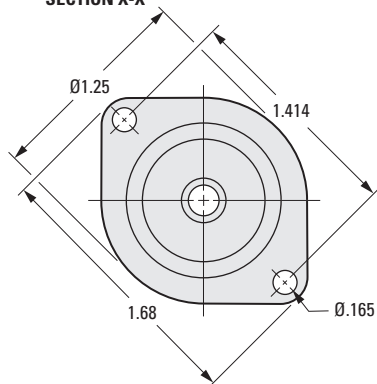

 INCH COMPONENT		Base Type
Catalog Number		
Aluminum	Steel	
A10Z40-1210B1	—	Square 
A10Z40-1210C1	A10Z40-1210C3	
A10Z40-1210D1	—	
A10Z40-1210A2	—	Diamond 
A10Z40-1210B2	A10Z40-1210B4	
A10Z40-1210C2	A10Z40-1210C4	
A10Z40-1210D2	A10Z40-1210D4	

Load Rating	Maximum Load lbf	Forcing Frequency in Cycles per Minute			
		1900	2500	3000	4000
		Minimum Load for 81% Isolation (lbf)			
A	4	4	2	1.5	1
B	8	8	4	3.0	2
C	12	12	7	5.0	3
D	20	20	11	8.0	5

NOTE: The above platemounts are available in Neoprene as a special order (200 pc. minimum).

