
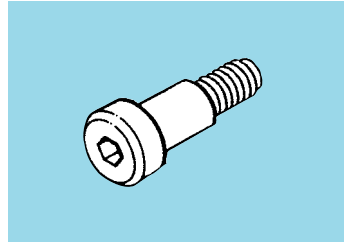


CLASS 3A THREAD

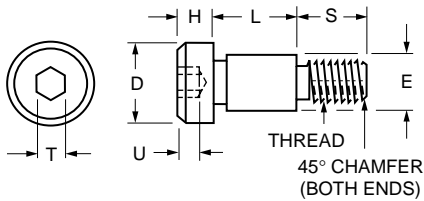

MATERIAL: 303 Stainless Steel

Catalog Number	Thread Size	D Dia. ±.010	E Dia. ±.0005	Dimensions				
				H ±.010	L ±.001	S ±.010	T	U
S7092Y-G44-0404 S7092Y-G44-0406 S7092Y-G44-0408 S7092Y-G44-0410 S7092Y-G44-0412	#4-40 UNC-3A	.250	.1240	.125	.1265 .1890 .2515 .3140 .3765	.156	5/64	1/16
S7092Y-G44-0604 S7092Y-G44-0606 S7092Y-G44-0608 S7092Y-G44-0610 S7092Y-G44-0612 S7092Y-G44-0616 S7092Y-G44-0620 S7092Y-G44-0624 S7092Y-G44-0632 S7092Y-G44-0640 S7092Y-G44-0648	#8-32 UNC-3A	.313	.1865	.156	.1265 .1890 .2515 .3140 .3765 .5015 .6265 .7515 1.0015 1.2515 1.5015	.188	3/32	5/64
S7092Y-G44-0804 S7092Y-G44-0806 S7092Y-G44-0808 S7092Y-G44-0810 S7092Y-G44-0812 S7092Y-G44-0816 S7092Y-G44-0820 S7092Y-G44-0824 S7092Y-G44-0832 S7092Y-G44-0840 S7092Y-G44-0848	#10-32 UNF-3A	.375	.2490	.188	.1265 .1890 .2515 .3140 .3765 .5015 .6265 .7515 1.0015 1.2515 1.5015	.250	1/8	3/32
S7092Y-G44-1008 S7092Y-G44-1010 S7092Y-G44-1012 S7092Y-G44-1016 S7092Y-G44-1020 S7092Y-G44-1024 S7092Y-G44-1210 S7092Y-G44-1212 S7092Y-G44-1216 S7092Y-G44-1220	1/4-20 UNC-3A	.500	.3115 .3740	.219 .219	.2515 .3140 .3765 .5015 .6265 .7515 .3140 .3765 .5015 .6265	.438 .438	5/32 5/32	1/8 1/8
S7092Y-G44-1210A S7092Y-G44-1212A S7092Y-G44-1216A S7092Y-G44-1220A	5/16-18 UNC-3A	.563	.3740	.250	.3140 .3765 .5015 .6265	.500	3/16	5/32
S7092Y-G44-1616 S7092Y-G44-1620 S7092Y-G44-1624 S7092Y-G44-1632	3/8-16 UNC-3A	.750	.4990	.313	.5015 .6265 .7515 1.0015	.625	1/4	3/16