



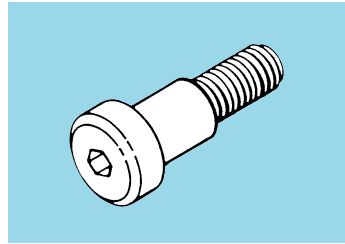

**INCH**

**Socket Head Shoulder Screws**

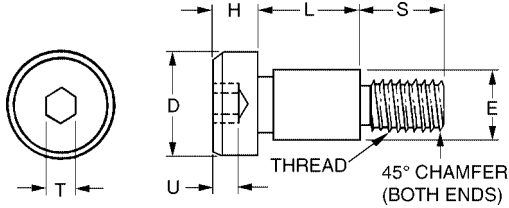

**MATERIAL: 303 Stainless Steel**

Catalog Number	Thread Size	D Dia.	E <sup>+0.000</sup> / <sub>-0.003</sub> Dia.	H	L <sup>+0.005</sup> / <sub>-0.000</sub>	S	T	U	
A 9X25-0404	#4-40	1/4	.125	1/8	.125	5/32	5/64	1/16	
A 9X25-0406					.188				
A 9X25-0408					.250				
A 9X25-0410					.312				
A 9X25-0412					.375				
A 9X25-0604	#8-32	5/16	.187	5/32	.125	3/16	3/32	5/64	
A 9X25-0606					.188				
A 9X25-0608					.250				
A 9X25-0610					.312				
A 9X25-0612					.375				
A 9X25-0616					.500				
A 9X25-0620					.625				
A 9X25-0624					.750				
A 9X25-0632					1.000				
A 9X25-0640					1.250				
A 9X25-0648	1.500								
A 9X25-0804	#10-32	3/8	.250	3/16	.125	1/4	1/8	3/32	
A 9X25-0806					.188				
A 9X25-0808					.250				
A 9X25-0810					.312				
A 9X25-0812					.375				
A 9X25-0816					.500				
A 9X25-0820					.625				
A 9X25-0824					.750				
A 9X25-0832					1.000				
A 9X25-0840					1.250				
A 9X25-0848	1.500								
A 9X25-1008	1/4-20	1/2	.312	7/32	.250	7/16	5/32	1/8	
A 9X25-1010					.312				
A 9X25-1012					.375				
A 9X25-1016					.500				
A 9X25-1020					.625				
A 9X25-1024		.750							
A 9X25-1210				.375					.312
A 9X25-1212									.375
A 9X25-1216									.500
A 9X25-1220									.625
A 9X25-1210A	.312								
A 9X25-1212A	.375								
A 9X25-1216A	.500								
A 9X25-1220A	.625								
A 9X25-1616	3/8-16	3/4	.500	5/16	.500	5/8	1/4	3/16	
A 9X25-1620					.625				
A 9X25-1624					.750				
A 9X25-1632					1.000				