


■ ALLOY STEEL

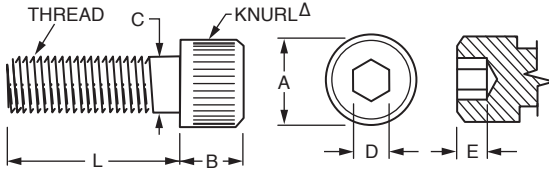

MATERIAL: Alloy Steel

FINISH: Black Oxide

Priced Per 100 Pieces

Catalog Number	Thread Size	L Length	A Max.	B Max.	C Max.	D Nom.	E Min.
A 9Q26-025608	#2-56	1/4	.140	.086	.086	5/64	.038
A 9Q26-025612		3/8					
A 9Q26-034812	#3-48	3/8	.161	.099	.099	5/64	.044
A 9Q26-034816		1/2					
A 9Q26-044008	#4-40	1/4	.183	.112	.112	3/32	.051
A 9Q26-044012		3/8					
A 9Q26-044016		1/2					
A 9Q26-044024		3/4					
A 9Q26-063208	#6-32	1/4	.226	.138	.138	7/64	.064
A 9Q26-063216		1/2					
A 9Q26-063220		5/8					
A 9Q26-063224		3/4					
A 9Q26-064008	#6-40	1/4	.226	.138	.138	7/64	.064
A 9Q26-064016		1/2					
A 9Q26-064020		5/8					
A 9Q26-064024		3/4					
A 9Q26-083212	#8-32	3/8	.270	.164	.164	9/64	.077
A 9Q26-083216		1/2					
A 9Q26-083224		3/4					
A 9Q26-083232		1					
A 9Q26-102416	#10-24	1/2	.312	.190	.190	5/32	.090
A 9Q26-102420		5/8					
A 9Q26-102424		3/4					
A 9Q26-102432		1					
A 9Q26-103212	#10-32	3/8	.312	.190	.190	5/32	.090
A 9Q26-103216		1/2					
A 9Q26-103224		3/4					
A 9Q26-103232		1					
A 9Q26-252016	1/4-20	1/2	.375	.250	.250	3/16	.120
A 9Q26-252024		3/4					
A 9Q26-252032		1					
A 9Q26-252048		1-1/2					
A 9Q26-311816	5/16-18	1/2	.468	.312	.312	1/4	.151
A 9Q26-311824		3/4					
A 9Q26-311832		1					
A 9Q26-311848		1-1/2					
A 9Q26-311856		1-3/4					
A 9Q26-371624	3/8-16	3/4	.562	.375	.375	5/16	.182
A 9Q26-371632		1					
A 9Q26-371648		1-1/2					

^ΔHead may be supplied with or without knurl at SDP option