
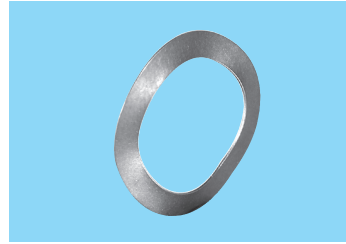


■ THIN WALL SERIES

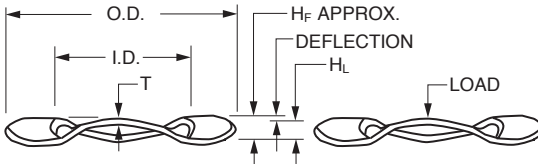


MATERIAL: 302 Stainless Steel (MIL-S-5057), Unfinished.

Priced Per 10 Pieces

Catalog Number	I.D.	O.D.	T Stock Thick.	H _f Free Height	H _L Loaded Height	Load @ H _L lb.	Use Inside Bore Ref.
A 7X 9-3W03606	.265	.367	.006	.030	.015	2 - 4	3/8
A 7X 9-3W04907	.350	.492	.007	.035	.020	3 - 5	1/2
A 7X 9-3W06108	.440	.618	.008	.040	.025	3 - 5	5/8
A 7X 9-3W07309	.531	.734	.009	.050	.030	4 - 7	3/4
A 7X 9-3W08510	.650	.855	.010	.060	.030	4 - 7	7/8
A 7X 9-3W11012	.856	1.102	.012	.075	.037	9 - 13	1-1/8

NOTE: O.D. and I.D. are blank (before bend) dimensions.

■ SCREW SIZE SERIES

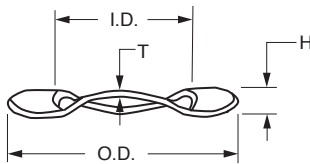

Priced Per 100 Pieces

Catalog Number		I.D.	O.D.	T	H	Nominal Screw Size
Beryllium Copper	Stainless Steel					
AB3401-EA150X006	AB3401-XP150X006	.075	.150	.006	.017	0
AB3401-EA206X006	AB3401-XP206X006	.095	.206		.018	2
AB3401-EA250X006	AB3401-XP250X006	.125	.250		.021	4
AB3401-EA265X006	AB3401-XP265X006	.134	.265		.021	5
AB3401-EA300X008	AB3401-XP300X008	.152	.300		.008	.028
AB3401-EA340X010	AB3401-XP340X010	.176	.340	.010	.030	8
AB3401-EA375X012	AB3401-XP375X012	.203	.375	.012	.032	10
AB3401-EA500X014	AB3401-XP500X014	.266	.500	.014	.042	1/4
AB3401-EA600X014	AB3401-XP600X014	.332	.600	.014	.052	5/16
AB3401-EA700X022	AB3401-XP700X022	.406	.700	.022	.064	3/8
AB3401-EA950X022	AB3401-XP950X022	.531	.950	.022	.076	1/2