
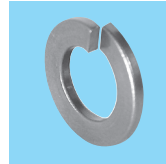


■ ASME B18.21.1

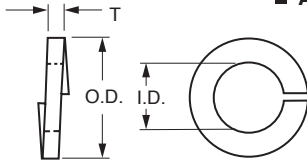

**MATERIAL:** Stainless Steel

Priced Per 100 Pieces

Catalog Number	Screw Size Ref.	I.D.	O.D.	T min.
*A 9X19-00	#0	.062	.137	.017
A 9X19-02	#2	.094	.172	.020
A 9X19-04	#4	.120	.209	.025
A 9X19-06	#6	.148	.250	.031
A 9X19-08	#8	.174	.293	.040
*A 9X19-10	#10	.200	.334	.047
A 9X19-25	1/4	.260	.487	.062
A 9X19-31	5/16	.322	.583	.078
A 9X19-37	3/8	.385	.680	.094

\*Special Sizes

■ ASME B18.21.1

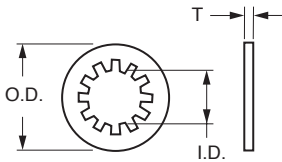


Fig. 1 (Internal)


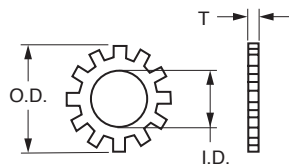


Fig. 2 (External)

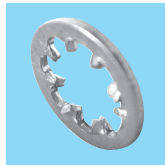

**MATERIAL:** Stainless Steel

Priced Per 100 Pieces

Catalog Number	Fig. No.	I.D. Screw Size	O.D.	T	
				min.	max.
A 9X21-I02	1	#2	.200	.010	.015
A 9X21-I04		#4	.270	.015	.019
A 9X21-I06		#6	.295	.017	.021
A 9X21-I08		#8	.340	.018	.023
A 9X21-I10		#10	.381	.020	.025
A 9X21-I25		1/4	.478	.023	.028
A 9X21-I31		5/16	.610	.028	.034
A 9X21-I38A		3/8	.692	.032	.040
A 9X21-I38B		3/8	.562	.032	.040
A 9X21-E04	2	#4	.260	.015	.019
A 9X21-E06		#6	.320	.016	.022
A 9X21-E08		#8	.381	.018	.023
A 9X21-E10		#10	.410	.020	.025
A 9X21-E25		1/4	.510	.023	.028
A 9X21-E38		3/8	.694	.032	.040