
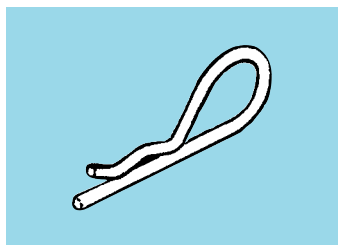


INTERNAL

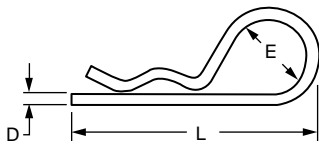


MATERIAL: Spring Wire, Oil-Tempered

FINISH: Plated

Priced Per 1000 Pieces

Catalog Number	D Diameter	Drill Hole Size	Recommended Shaft Diameter		E Inside Diameter of Eye	L Length
			Minimum	Maximum		
A 9Q34-23	.042	3/64	3/16	1/4	1/4	1
A 9Q34-21	.047	1/16	1/8	3/16	1/8	19/32
A 9Q34-22	.062	5/64	1/4	1/2	5/16	1-5/16
A 9Q34-18		3/8	1-9/16			
A 9Q34-13	.080	3/32	1/4	3/8	1/4	1-3/16
A 9Q34-17			3/8	1/2	5/16	1-9/16
A 9Q34-03	.093	7/64	1/4	1/2	3/8	1-5/8
A 9Q34-07			1/4	5/8	5/8	2-5/16
A 9Q34-14			3/8	3/4	7/16	2-1/2

EXTERNAL

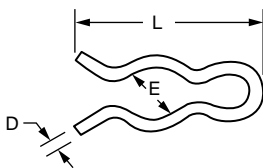

MATERIAL: Spring Wire, Oil-Tempered

FINISH: Plated

Priced Per 1000 Pieces

Catalog Number	D Diameter	Recommended Groove Dimensions		E Inside Diameter of Eye	L Length
		Diameter	Width		
A 9Q34-X1	.032	5/32	3/64	1/8	15/32
A 9Q34-X2	.062	3/8	5/64	5/16	1
A 9Q34-X3		1/4		3/16	11/16
A 9Q34-X4	.047	1/4	1/16	3/16	7/8

Other materials available on special order.