

FLANGED SILICONE GEL VIBRATION DAMPERS



TO BE USED IN COMPRESSION ONLY
 FOR SMALL TO INTERMEDIATE LOAD APPLICATIONS
 DAMPS LOW FREQUENCY VIBRATION
 CAN BE USED WHEN SPACE IS LIMITED

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM





> MATERIAL:

- Stud** - Stainless Steel
- Body** - Silicone Gel
- Flange Plate** - Stainless Steel

> OPERATING TEMPERATURE:

-40°F to +392°F

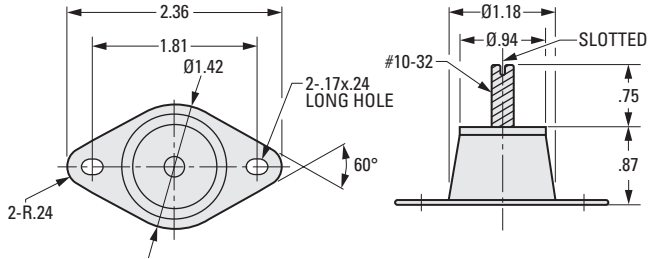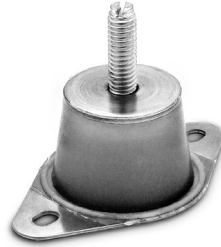


INCH COMPONENT

Catalog Number	Optimum Load lbf/leg
A10Z64-SF02	2.8 to 7.2
A10Z64-SF05	7.2 to 16.5
A10Z64-SF10	16.5 to 27.6

TYPICAL CHARACTERISTICS OF THE SILICONE MOUNTS

(Example Shown: A10Z64-MN05)

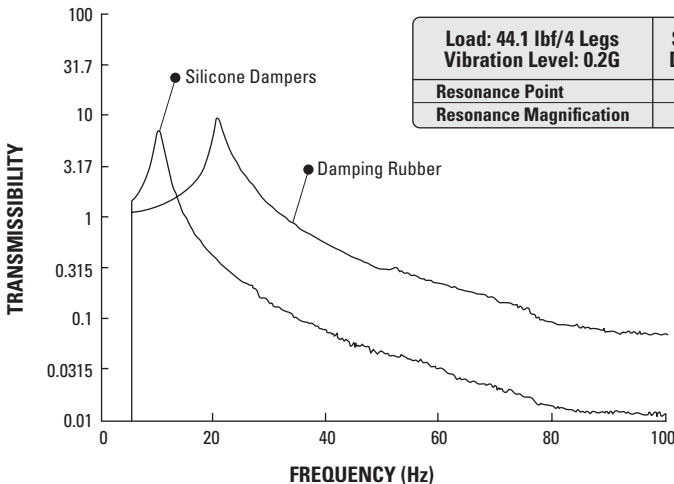

8-07
D820

REV:
3/31/23

- I
- R
- T
- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16