


PINIONS – MODULE 0.4

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

ISO CLASS 10
HUBLESS
4 mm FACE WIDTH
20° PRESSURE ANGLE



► **MATERIAL:**
Brass

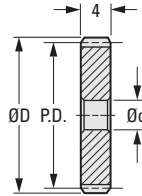

METRIC COMPONENT

Catalog Number	No. of Teeth	P.D.	D Dia.	d Bore +0.025 0
A 1B 1MY04008	8	3.2	4	1.5
A 1B 1MY04010	10	4	4.8	2
A 1B 1MY04012	12	4.8	5.6	3
A 1B 1MY04014	14	5.6	6.4	
A 1B 1MY04016	16	6.4	7.2	
A 1B 1MY04018	18	7.2	8	
A 1B 1MY04024	24	9.6	10.4	

PINION SHAFTS


UNDERSIZED DIAMETER

► **MATERIAL:**
303 Stainless Steel



► **STRAIGHTNESS:**
0.0003 mm/mm

Discounts available for large quantity orders.

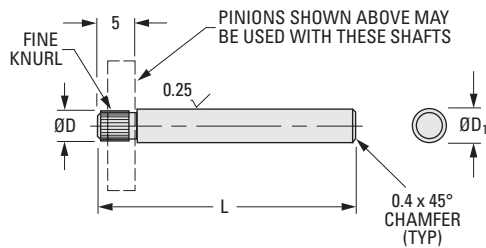

METRIC COMPONENT

Catalog Number	D Dia. +0.025 0	D ₁ Dia. -0.004 -0.012	L Length ± 0.25
A 7X 1MP0550A	1.5	5	50
A 7X 1MP0550B	2		
A 7X 1MP0675	3	6	75

- I
- R
- T
- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16