

I

## NONMETALLIC HUBLESS SPUR GEARS • MODULE 1

SDP/SI

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

R

ISO CLASS 7  
5 mm FACE WIDTH  
10 mm BORE  
20° PRESSURE ANGLE

T

➤ **MATERIAL:**  
Gear – Acetal

1

Available as special order:  
14-1/2° P.A., teeth not listed  
or different bore size, or  
assembled onto Fairloc® Integral  
Fastener hub or pin type hub.

2

3

4

**METRIC COMPONENT  
CATALOG NUMBER**
S 1 2 M 1 0 M    N 0 5 1 0

No. of  
Teeth  
Code

5

6

7

8

9

10

11



12

13

14

15

A

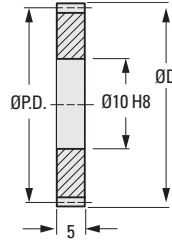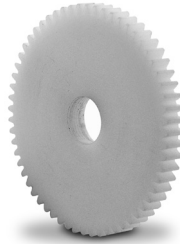

0 10  
S Precision  
Component

No. of Teeth Code	No. of Teeth	P.D.	D Dia.
015	15	15	17
016	16	16	18
018	18	18	20
020	20	20	22
021	21	21	23
022	22	22	24
023	23	23	25
024	24	24	26
025	25	25	27
028	28	28	30
030	30	30	32
032	32	32	34
035	35	35	37
036	36	36	38
040	40	40	42
042	42	42	44
045	45	45	47
046	46	46	48
048	48	48	50
050	50	50	52
052	52	52	54
056	56	56	58
060	60	60	62
064	64	64	66
066	66	66	68
069	69	69	71
070	70	70	72
072	72	72	74
078	78	78	80
080	80	80	82
084	84	84	86
090	90	90	92
093	93	93	95
100	100	100	102