


ROUND RACKS – MODULE 0.5 TO 1

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

ISO CLASS 9
20° PRESSURE ANGLE

> **MATERIAL:**
304 Stainless Steel

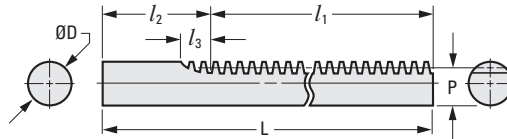

I
R
T
1

2
3

4
5

6
7

8
9

10
11

12
13

14
15

16



METRIC COMPONENT

Catalog Number	Module	D h7 (± 0.015)	P Pitch Height	l	l ₂ Ref.	l ₃	L Length mm ± 1
S181YYM0508200	0.5	8	7.5	149	53	10.7	202
S181YYM0758200	0.75		7.25	148	54	13	
S181YYM0808200	0.8		7.2			13.4	
S181YYM100A300	1	10	9	238	67	15	305

NONMETALLIC RACKS - MODULE 0.4 TO 3

20° PRESSURE ANGLE
 
> **MATERIAL:**
Molded Acetal
Machined Cast Nylon

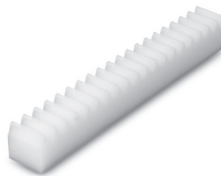

METRIC COMPONENT

Catalog Number	Module	Material	S Face Width	H Height	P Pitch Height	L Length mm	
A 1M12MYP0425	0.4	Acetal (Molded)	3	3.9	3.5	250	
A 1M12MYZ0525	0.5		4	4.5	4		
A 1M12MYZ0525A			4	6	5.5		
A 1M12MYZ0725	0.7		6	6.7	6		
A 1M12MYP0825	0.8		5	7.3	6.5		
A 1M12MYZ1025	1		9	9	8		
A 1M12MYZ1225	1.25		10	11	9.75		
A 1M12MYZ1525	1.5		12	12	10.5		
A 1M12MYZ2025	2		15.4	11	9		
A 1M12MYZ3025	3		19.4	15	12		
A 1M12MYH100500	1		10	12	11		505
A 1M12MYH150500	1.5		15	20	18.5		
A 1M12MYH151000		1010					
A 1M12MYH200500	2	Nylon (Machined)	20	25	23	505	
A 1M12MYH201000			1010				
A 1M12MYH250500	2.5		25	30	27.5	505	
A 1M12MYH251000						1010	
A 1M12MYH300500	3		30	35	32	505	
A 1M12MYH301000						1010	