

ISO CLASS 8
 WORM GEARS – RIGHT- AND LEFT-HAND
 WITH OR WITHOUT KEYWAY
 20° PRESSURE ANGLE

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM




0 10

QUALITY CLASS

> MATERIAL:

Aluminum Bronze

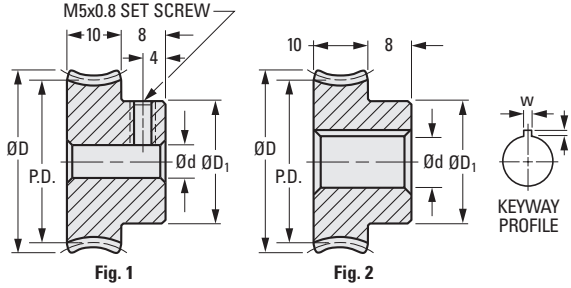

METRIC COMPONENT

Catalog Number*	Thread Data				No. of Teeth	P.D.	D Dia.	d Bore H8	d Tol.	D ₁ Hub Dia.
	Sgl. Thd.	Dbl. Thd.	Right-Hand	Left-Hand						
Fig. 1 Worm Gears – Right- and Left-Hand – Aluminum Bronze										
A 1B 6MYK10R020	•		•		20	20	23.5	6	+0.018/0	17
A 1B 6MYK10L020				•						
A 1B 6MYK10L030	•			•	30	30	33.5	6	+0.018/0	22

Catalog Number*	Thread Data			No. of Teeth	P.D.	D Dia.	d Bore H8	d Tolerance	D ₁ Hub Dia.	w	t
	Sgl. Thd.	Dbl. Thd.									
Fig. 2 Worm Gears – With Keyway – Right-Hand – Aluminum Bronze											
A 1B66MYK10R030	•			30	30	33.5	10	+0.022/0	22	3	1.4
A 1B66MWK10R030		•									
A 1B66MYK10R040	•			40	40	43.5	10	+0.022/0	25	3	1.4

*To be discontinued when present stock is depleted.

- I
- R
- T
- 1**
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- A