

USED IN LINEAR DRIVES

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

> MATERIAL:

Aluminum

> SPECIFICATIONS:

Timing belt clamp kit includes:

Top and bottom plate and hardware for assembly.

Hardware for kit includes:

Screws, washers and hex nuts for assembly.


For replacement hardware kit, order:

A16A55MBOLTKIT GT² 5 mm pitch

A16A58MBOLTKIT GT² 8 mm pitch



5 mm Pitch						
F mm (in.)	M mm (in.)	S mm (in.)	H Dia. mm (in.)	K mm (in.)	X mm (in.)	S ₁ mm (in.)
7.5 (.295)	10 (.394)	8 (.315)	10 (.394)	25 (.984)	5 (.197)	10 (.394)
8 mm Pitch						
10 (.394)	16 (.630)	15 (.591)	15 (.591)	40 (1.575)	8 (.315)	16 (.630)

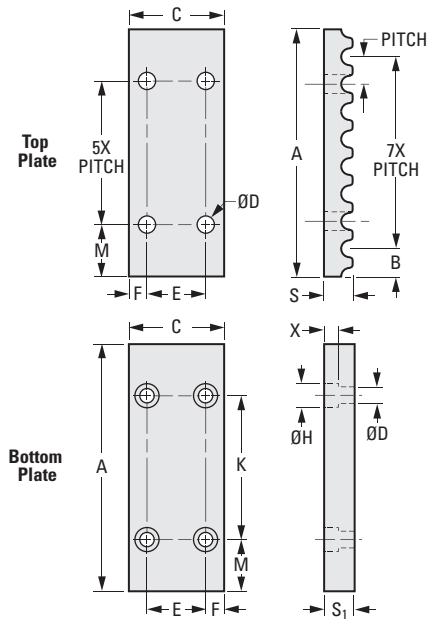

METRIC COMPONENT

Catalog Number	Belt Width mm (in.)	A mm (in.)	B mm (in.)	C mm (in.)	D Dia. mm (in.)	E mm (in.)	Toothed + Flat Plate Total Weight (with hardware) kg (lb.)
GT² • 5 mm Pitch - Sold as Kit							
A16A55M09	9 (.354)	45 (1.772)	5 (.197)	30.5 (1.201)	5.5 (.217)	15.5 (.610)	0.056 (.12)
A16A55M15	15 (.591)	45 (1.772)	5 (.197)	37 (1.457)	5.5 (.217)	22 (.866)	0.074 (.16)
A16A55M25	25 (.984)	45 (1.772)	5 (.197)	47 (1.850)	5.5 (.217)	32 (1.260)	0.096 (.21)
GT² • 8 mm Pitch - Sold as Kit							
A16A58M20	20 (.787)	72 (2.835)	8 (.315)	50.5 (1.988)	9 (.354)	30.5 (1.201)	0.272 (.60)
A16A58M30	30 (1.181)	72 (2.835)	8 (.315)	60.5 (2.382)	9 (.354)	40.5 (1.594)	0.334 (.73)
A16A58M50	50 (1.968)	72 (2.835)	8 (.315)	81 (3.189)	9 (.354)	61 (2.401)	0.448 (.99)

