

# IDLER ROLLERS

# SDP/SI

WITH BALL BEARING SUPPORTS

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM


**> MATERIAL:**

Steel, Aluminum or Nylon

**> SPECIFICATION:**

Max. operating speed: 6000 rpm

Washers, nut and bolt supplied with rollers.

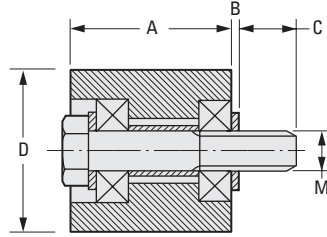

**NEW**

METRIC COMPONENT			Dimensions in ( ) are inch.				
Catalog Number			A	B	C	D	M
Steel	Aluminum	Nylon					
A 6C 9M03008	A 6A 9M03008	A 6Z 9M03008	35 (1.38)	2.5 (.10)	13.5 (.53)	30 (1.18)	M8
—	—	A 6Z 9M04010	45 (1.77)	2 (.08)	16 (.63)	40 (1.57)	M10
A 6C 9M05012	A 6A 9M05012	A 6Z 9M05012	50 (1.97)	2.5 (.10)	18 (.71)	50 (1.97)	M12
A 6C 9M06012	A 6A 9M06012	A 6Z 9M06012	60 (2.36)			60 (2.36)	
A 6C 9M08012	A 6A 9M08012	A 6Z 9M08012	90 (3.54)			80 (3.15)	

- I
- R
- T
- 1
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16