


BELT WIDTHS
INCH - 1/8, 3/16, 1/4, 5/16, & 3/8
NON-MARKING
LOW DUST
RoHS COMPLIANT
PowerGrip® TruMotion®

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

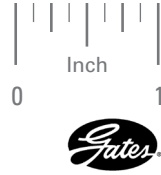

> MATERIAL:

Cream-Colored Polymer Compound, Fiberglass
Reinforced Body with Nylon Tooth Facing for Reduced Dust.

> SPECIFICATIONS:

Breaking Strength:
51 lbf per 1/8 in. (72 N per 1 mm) belt width;
not representative of the load-carrying
capacity of the belt.

Working Tension:
15 lbf for 1 in. belt (67 N for 25.4 mm belt)


For more information, see the technical section.

Temperature Range:
-40°F to +220°F (-40°C to +104°C)

> MODIFICATIONS:

Special Widths - cut to size from
sleeves available from stock.

Pulleys are available with inch
or metric standards.

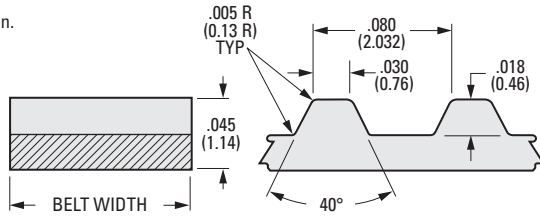

NOTE: Dimensions in () are mm.

**INCH COMPONENT
CATALOG NUMBER**

A 2 6 Z 1 6 -

No. of
Grooves
Code

Belt Width Inch	Width Code
1/8	012
3/16	018
1/4	025
5/16	031
3/8	037

Groove Code	Pitch Length	
	Inch	mm
040	3.20	81.28
109	8.72	221.49
400	32.00	812.8