

BELT WIDTHS
 INCH - 1/4, 5/16 & 3/8
 NON-MARKING
 LOW DUST
 RoHS COMPLIANT
 PowerGrip® TruMotion®

> MATERIAL:

Cream-Colored Polymer Compound, Fiberglass
 Reinforced Body with Nylon Tooth Facing for Reduced Dust.

> SPECIFICATIONS:

Breaking Strength:

113 lbf per 1/8 in. (158 N per 1 mm) Belt Width;
 not representative of the load-carrying capacity of the belt.

Working Tension:

23 lbf for 1 in. belt (102 N for 25.4 mm Belt)
 For more information, see the technical section.


Temperature Range:

-40°F to +220°F (-40°C to +104°C)

> MODIFICATIONS:

Special Widths - cut to size from
 sleeves available from stock.

Pulleys are available with inch
 or metric standards.

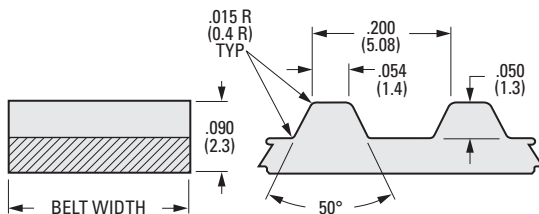

NOTE: Dimensions in () are mm.

**INCH COMPONENT
 CATALOG NUMBER**

A 2 6 R 3 -

No. of
 Grooves
 Code

Belt Width Inch	Width Code
1/4	025
5/16	031
3/8	037

Groove Code	Pitch Length	
	Inch	mm
065	13.0	330.2
092	18.4	467.36
093	18.6	472.44
133	26.6	675.64