

SINGLE CORE

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

> **MATERIAL:**

Body - Molded Polyurethane
Core - Aramid Fiber or Stainless Steel



> **SPECIFICATIONS:**

Operating Temperature Range:
 -23°C to +60°C

BELT DATA


Belt Core	Belt Core Code	Min. No. of Teeth in Mesh	Min. Pulley Dia.	Max. Belt Operating Speed No Load/Load m/min.	Max. Operating Belt Tension N
Aramid	AF	6	19.1	335/152	23
Steel	SS	6	19.1	335/183	45



These belts are also sold by the meter, in continuous lengths up to 30.4 meters.

Catalog Number	Belt Core
S7913YM20AF	Aramid Fiber
S7913YM20SS	Stainless Steel

CORE:
SS, STAINLESS STEEL FOR LOWEST STRETCH...OR
AF, ARAMID FIBER FOR HIGHEST FLEXIBILITY & SPEED

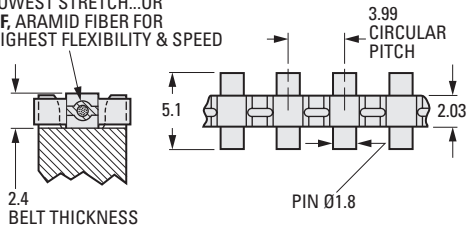

METRIC COMPONENT CATALOG NUMBER

S 7 9 1 3 Y M 2 0 □ □ □ □

Aramid Fiber Core **AF**
 Stainless Steel Core **SS**
 No. of Drive Pins

No. of Drive Pins	Pitch Length
030	119.7
035	139.6
040	159.6
045	179.5
050	199.5
055	219.4
060	239.4
070	279.3
080	319.2
090	359.1
100	399
110	438.9
120	478.8
130	518.7
140	558.6
150	598.5
160	638.4
170	678.3
180	718.2
190	758.1
200	798

No. of Drive Pins	Pitch Length
210	837.8
220	877.7
230	917.7
240	957.6
250	997.5
260	1037.3
270	1077.2
280	1117.1
290	1157
300	1196.9
310	1236.8
320	1276.7
330	1316.6
340	1356.5
350	1396.4
360	1436.3
370	1476.2
380	1516.1
400	1595.9
420	1675.7
440	1755.5