

O-RINGS

SDP/SI

FOR USE WITH FRELON® LINED
LINEAR BEARINGS

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

> **MATERIAL:**

Neoprene, Approx. 70 Durometer

> **SPECIFICATIONS:**


Operating Temperature: -54°C to +99°C

10% elongation is permissible.




METRIC COMPONENT

Catalog Number	D Dia.	d Dia.
A 6R11ML009713	1.3	9.7
A 6R11ML016015	1.5	16
A 6R11ML025015	1.5	25
A 6R11ML018015	1.5	18
A 6R11ML014116	1.6	14.1
A 6R11ML021116	1.6	21.1
A 6R11ML013017	1.7	13
A 6R11ML012817	1.78	12.83
A 6R11ML011819	1.96	11.89
A 6R11ML015520	2	15.5
A 6R11ML017525	2.5	17.5
A 6R11ML021525	2.5	21.5
A 6R11ML027525	2.5	27.5
A 6R11ML030525	2.5	30.5
A 6R11ML035525	2.5	35.5
A 6R11ML042526	2.62	42.52
A 6R11ML046035	3.5	46
A 6R11ML056035	3.5	56
A 6R11ML069035	3.5	69
A 6R11ML081050	5	81

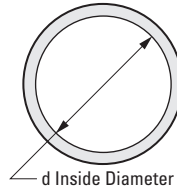

Cross-Section

 

- I
- R
- T
- 1
- 2**
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- A