

DIN 84


PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

> MATERIAL:

304 Stainless Steel

> SPECIFICATION:

Priced Per 100 Pieces

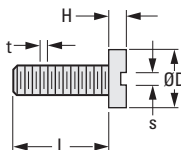

METRIC COMPONENT

Catalog Number	Thread Size	L Length
MD0084MXO016X004	M1.6	4
MD0084MXO016X006	M1.6	6
MD0084MXO020X003	M2	3
MD0084MXO020X004	M2	4
MD0084MXO020X005	M2	5
MD0084MXO020X006	M2	6
MD0084MXO020X008	M2	8
MD0084MXO020X010	M2	10
MD0084MXO020X016	M2	16
MD0084MXO020X020	M2	20
MD0084MXO025X005	M2.5	5
MD0084MXO025X006	M2.5	6
MD0084MXO025X008	M2.5	8
MD0084MXO025X010	M2.5	10
MD0084MXO025X012	M2.5	12
MD0084MXO025X016	M2.5	16
MD0084MXO025X020	M2.5	20
MD0084MXO030X005	M3	5
MD0084MXO030X006	M3	6
MD0084MXO030X008	M3	8
MD0084MXO030X010	M3	10
MD0084MXO030X012	M3	12
MD0084MXO030X020	M3	20
MD0084MXO030X025	M3	25
MD0084MXO035X008	M3.5	8
MD0084MXO035X012	M3.5	12

Catalog Number	Thread Size	L Length
MD0084MXO035X016	M3.5	16
MD0084MXO040X006	M4	6
MD0084MXO040X008	M4	8
MD0084MXO040X010	M4	10
MD0084MXO040X012	M4	12
MD0084MXO040X016	M4	16
MD0084MXO040X020	M4	20
MD0084MXO040X025	M4	25
MD0084MXO040X030	M4	30
MD0084MXO040X035	M4	35
MD0084MXO040X040	M4	40
MD0084MXO050X010	M5	10
MD0084MXO050X012	M5	12
MD0084MXO050X016	M5	16
MD0084MXO050X020	M5	20
MD0084MXO050X025	M5	25
MD0084MXO050X030	M5	30
MD0084MXO050X035	M5	35
MD0084MXO050X040	M5	40
MD0084MXO060X008	M6	8
MD0084MXO060X010	M6	10
MD0084MXO060X012	M6	12
MD0084MXO060X016	M6	16
MD0084MXO060X020	M6	20
MD0084MXO060X025	M6	25
MD0084MXO060X030	M6	30

Dimensions	Thread Size							
	M1.6	M2	M2.5	M3	M3.5	M4	M5	M6
t	0.35	0.4	0.45	0.5	0.6	0.7	0.8	1
D	3	3.8	4.5	5.5	6	7	8.5	10
H	1	1.3	1.6	2	2.5	2.6	3.3	3.6
s	0.4	0.5	0.6	0.8	0.9	1	1.2	1.6

I

R

T

1

2

3

4

5

6

7

8

9

10

11

12

13

14

15

A