



SINGLE-POINT CONTACT

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM


> MATERIAL:

Body - Carbon Steel, Black Oxide Finish;
304 Stainless Steel

Ball - Carbon Steel, HRC 56...60;
440C Stainless Steel, HRC 55...60

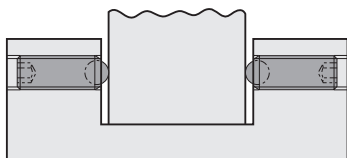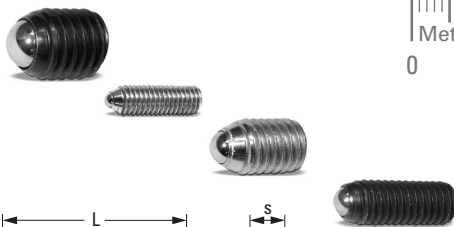

Example of application to fasten work piece that damages easily.

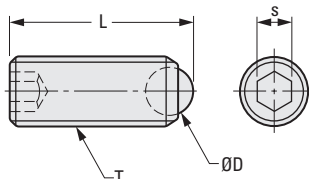

The projections shown are per ISO convention.

METRIC COMPONENT

Catalog Number		T Thread	L	D Dia.	s Hex Size	Mass g
Carbon Steel	Stainless Steel					
S705CBM0305	S705YBM0305	M3 x 0.5	5.2	1.5	1.5	0.3
S705CBM0310	S705YBM0310	M3 x 0.5	10.2	1.5	1.5	0.6
S705CBM0407	S705YBM0407	M4 x 0.7	6.5	2.5	2	0.4
S705CBM0411	S705YBM0411	M4 x 0.7	10.5	2.5	2	0.7
S705CBM0417	S705YBM0417	M4 x 0.7	16.5	2.5	2	1
S705CBM0509	S705YBM0509	M5 x 0.8	8.6	3	2.5	0.8
S705CBM0513	S705YBM0513	M5 x 0.8	12.6	3	2.5	1.3
S705CBM0521	S705YBM0521	M5 x 0.8	20.6	3	2.5	2.3
S705CBM0611	S705YBM0611	M6 x 1	10.8	4	3	1.5
S705CBM0617	S705YBM0617	M6 x 1	16.8	4	3	2.5
S705CBM0621	S705YBM0621	M6 x 1	20.8	4	3	3.4
S705CBM0626	S705YBM0626	M6 x 1	25.8	4	3	4
S705CBM0811	S705YBM0811	M8 x 1.25	11.2	5.5	4	2.5
S705CBM0813	S705YBM0813	M8 x 1.25	13.2	5.5	4	3.2
S705CBM0821	S705YBM0821	M8 x 1.25	21.2	5.5	4	5.7
S705CBM0826	S705YBM0826	M8 x 1.25	26.2	5.5	4	7.7
S705CBM0831	S705YBM0831	M8 x 1.25	31.2	5.5	4	9
S705CBM1014	S705YBM1014	M10 x 1.5	13.7	7	5	5
S705CBM1018	S705YBM1018	M10 x 1.5	17.7	7	5	7
S705CBM1022	S705YBM1022	M10 x 1.5	21.7	7	5	9.5
S705CBM1027	S705YBM1027	M10 x 1.5	26.7	7	5	11
S705CBM1037	S705YBM1037	M10 x 1.5	36.7	7	5	16
S705CBM1218	S705YBM1218	M12 x 1.75	18	8.5	6	10
S705CBM1222	S705YBM1222	M12 x 1.75	22	8.5	6	12.5
S705CBM1232	S705YBM1232	M12 x 1.75	32	8.5	6	20
S705CBM1242	S705YBM1242	M12 x 1.75	42	8.5	6	28
S705CBM1623	S705YBM1623	M16 x 2	23.3	12	8	22
S705CBM1628	S705YBM1628	M16 x 2	28.3	12	8	28
S705CBM1638	S705YBM1638	M16 x 2	38.3	12	8	41
S705CBM1653	S705YBM1653	M16 x 2	53.3	12	8	48