

DIN 127 B
DIN 7980

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

► **MATERIAL:**

Spring Steel or
Stainless Steel

► **SPECIFICATION:**

Priced Per 100 Pieces

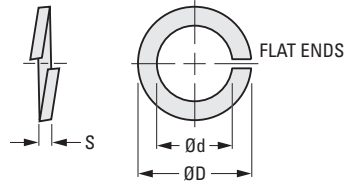


Fig. 1 DIN 127 B

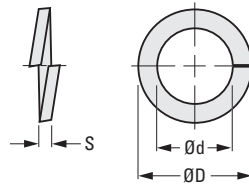


Fig. 2 DIN 7980

The projections shown are per ISO convention.

METRIC COMPONENT

Catalog Number		Screw Size Ref.	d Dia.	D Dia.	S
Spring Steel	Stainless Steel				
Fig. 1 DIN 127 B For Pan Head Screws					
MD0127MQB020	MD0127MXO020	M2	2.1	4.4	0.5
MD0127MQB025	MD0127MXO025	M2.5	2.6	5.1	0.6
MD0127MQB030	MD0127MXO030	M3	3.1	6.2	0.8
MD0127MQB040	MD0127MXO040	M4	4.1	7.6	0.9
MD0127MQB050	MD0127MXO050	M5	5.1	9.2	1.2
MD0127MQB060	MD0127MXO060	M6	6.1	11.8	1.6
MD0127MQB080	MD0127MXO080	M8	8.1	14.8	2
MD0127MQB100	MD0127MXO100	M10	10.2	18.1	2.2
MD0127MQB120	MD0127MXO120	M12	12.2	21.1	2.5
Fig. 2 DIN 7980 For Socket & Cheese Head Screws					
MD7980MQB030	MD7980MXO030	M3	3.1	5.6	1
MD7980MQB040	MD7980MXO040	M4	4.1	7	1.2
MD7980MQB050	MD7980MXO050	M5	5.1	8.8	1.6
MD7980MQB060	MD7980MXO060	M6	6.1	9.9	1.6
MD7980MQB080	MD7980MXO080	M8	8.1	12.7	2