

PRECISION BALANCED-TYPE SHAFT/HUB CLAMPS




- I
- R
- T
- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16

> MATERIAL:

- Carbon Steel, Zinc Plated
- 303 Stainless Steel
- 416 Stainless Steel (Rc 38-45)
- 416 Stainless Steel (Rc 38-45), Black Oxide


PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

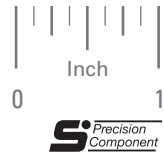

> SPECIFICATIONS:

Tolerances	
Decimals	± .005
Fractions	± 1/64

Stainless Steel socket head cap screw supplied.

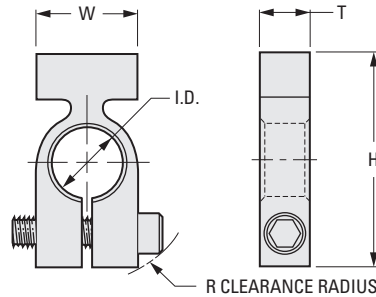

INCH COMPONENT

Catalog Number	Shaft Size	I.D.* +.001 -.000	H	T	W	Screw Size	R
Carbon Steel, Zinc Plated							
S3300Y-C098	1/8	.188	11/16	.140	.312	#2-56	27/64
S3300Y-C099	3/16	.251	51/64		.375		1/2
S3300Y-C100	1/4	.313	13/16		.437		33/64
S3300Y-C101	5/16	.376	7/8		.500		9/16
S3300Y-C102	3/8	.438	1-1/32		.625		41/64
S3300Y-C083	1/8	.188	11/16	.250	.312	#6-32	27/64
S3300Y-C084	3/16	.251	51/64		.375		1/2
S3300Y-C085	1/4	.313	13/16		.437		33/64
S3300Y-C086	5/16	.376	7/8		.500		9/16
S3300Y-C087	3/8	.438	1-1/32		.625		41/64
303 Stainless Steel							
S3300Y-C088	1/8	.188	11/16	.250	.312	#6-32	27/64
S3300Y-C089	3/16	.251	51/64		.375		1/2
S3300Y-C090	1/4	.313	13/16		.437		33/64
S3300Y-C091	5/16	.376	7/8		.500		9/16
S3300Y-C092	3/8	.438	1-1/32		.625		41/64
416 Stainless Steel (Rc 38-45)							
S3300Y-C160	1/8	.188	11/16	.240	.312	#6-32	27/64
S3300Y-C161	3/16	.250	13/16		.375		1/2
S3300Y-C162	1/4	.312	13/16		.437		33/64
416 Stainless Steel (Rc 38-45), Black Oxide							
S3300Y-C163	1/8	.188	11/16	.240	.312	#6-32	27/64
S3300Y-C164	3/16	.250	13/16		.375		1/2
S3300Y-C165	1/4	.312	13/16		.437		33/64

* Dimensions apply before slot is made.