

BELT WIDTHS

INCH - 1/4, 5/16, 3/8 & 1/2
 METRIC - 6, 8, 9.5 & 12.7 mm

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

> MATERIAL:

Neoprene - Nylon Covered, Fiberglass Reinforced

> SPECIFICATIONS:

Breaking Strength:

113 lbf per 1/8 in. (158 N per 1 mm) Belt Width;
 not representative of the load-carrying capacity of the belt.

Working Tension:

28 lbf for 1 in. belt (125 N for 25.4 mm belt).
 For more information, see the technical section.


Temperature Range:

30°F to +185°F (-34°C to +85°C)

> MODIFICATIONS:

Special Widths - cut to size from sleeves available from stock.

Pulleys are available with inch or metric standards.

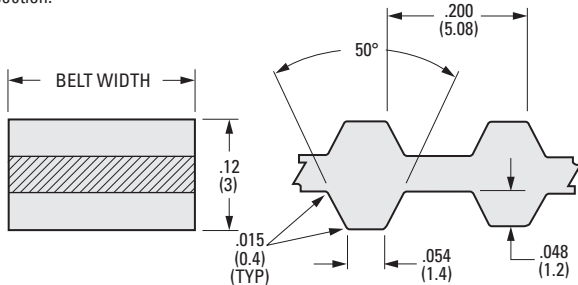

NOTE: Dimensions in () are mm.

INCH COMPONENT CATALOG NUMBER

A 6 R 3 - D

No. of Grooves Code

Belt Width Inch	Width Code
1/4	025
5/16	031
3/8	037
1/2	050

METRIC COMPONENT CATALOG NUMBER

A 6 R 3 M D

No. of Grooves Code

Belt Width mm	Width Code
6	060
8	080
9.5	095
12.7	127

Groove Code	Pitch Length	
	Inch	mm
035	7.0	177.8
040	8.0	203.2
050	10.0	254
055	11.0	279.4
060	12.0	304.8
065	13.0	330.2
070	14.0	355.6
075	15.0	381
080	16.0	406.4
085	17.0	431.8
090	18.0	457.2
095	19.0	482.6
100	20.0	508
105	21.0	533.4
110	22.0	558.8

Groove Code	Pitch Length	
	Inch	mm
115	23.0	584.2
120	24.0	609.6
125	25.0	635
130	26.0	660.4
140	28.0	711.2
145	29.0	736.6
150	30.0	762
155	31.0	787.4
165	33.0	838.2
181	36.2	919.48
195	39.0	990.6
196	39.2	995.68
225	45.0	1143
246	49.2	1249.68
345	69.0	1752.6

