

XL PULLEY FLANGES • 1/5" OR 5.08 mm PITCH

SDP/SI


> MATERIAL:

Aluminum Alloy or Steel

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

> SPECIFICATION:

Priced per 25 pieces

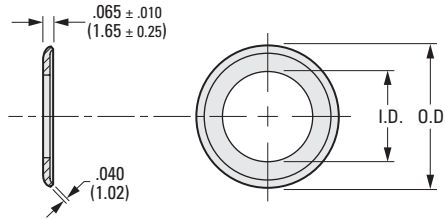

INCH COMPONENT

Catalog Number		Pulley Grooves Ref.	Inch		Metric	
Aluminum Alloy	Steel		I.D. ± .003	O.D. ± .015	I.D. ± 0.08	O.D. ± 0.4
A 6A 2-10FA	A 6C 2-10FS	10	.503	7/8	12.78	22.2
A 6A 2-11FA	A 6C 2-11FS	11	.562	15/16	14.27	23.8
A 6A 2-12FA	A 6C 2-12FS	12	.562	1	14.27	25.4
A 6A 2-13FA	A 6C 2-13FS	13	.625	1-1/16	15.88	27
A 6A 2-14FA	A 6C 2-14FS	14	.684	1-3/32	17.37	27.8
A 6A 2-15FA	A 6C 2-15FS	15	.748	1-3/16	19	30.2
A 6A 2-15FAX	A 6C 2-15FSX	15	.814	1-3/16	20.67	30.2
A 6A 2-16FA	A 6C 2-16FS	16	.810	1-1/4	20.58	31.8
A 6A 2-17FA	A 6C 2-17FS	17	.887	1-5/16	22.54	33.3
A 6A 2-18FA	A 6C 2-18FS	18	.936	1-3/8	23.77	34.9
A 6A 2-19FA	A 6C 2-19FS	19	1.000	1-7/16	25.4	36.5
A 6A 2-20FA	A 6C 2-20FS	20	1.062	1-1/2	26.97	38.1
A 6A 2-21FA	A 6C 2-21FS	21	1.125	1-9/16	28.58	39.7
A 6A 2-22FA	A 6C 2-22FS	22	1.160	1-5/8	29.46	41.3
A 6A 2-23FA	A 6C 2-23FS	23	1.222	1-11/16	31.04	42.8
A 6A 2-24FA	A 6C 2-24FS	24	1.222	1-3/4	31.04	44.5
A 6A 2-25FA	A 6C 2-25FS	25	1.250	1-13/16	31.75	46
A 6A 2-26FA	A 6C 2-26FS	26	1.347	1-7/8	34.21	47.8
A 6A 2-28FA	A 6C 2-28FS	28	1.425	2	36.2	50.8
A 6A 2-30FA	A 6C 2-30FS	30	1.550	2-1/8	39.37	54
A 6A 2-32FA	A 6C 2-32FS	32	1.675	2-1/4	42.55	57.2

NOTE: Dimensions in () are mm.

- I
- R
- T
- 1
- 2
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16