

**FOR 1/4" BELTS**  
DOUBLE FLANGE

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

**> MATERIAL:**

Aluminum Alloy


**> FINISH:**

Clear Anodized

**> SPECIFICATIONS:**

O.D. Tolerance: 10 to 16 grooves is  $+.002/-0.000$   
18 to 30 grooves is  $+.003/-0.000$

Pulleys with 10 & 11 grooves have 1 set screw;  
others have 2 set screws at 90°.

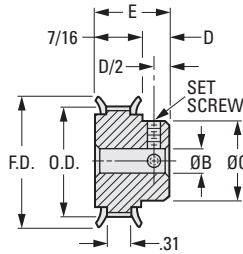

**INCH COMPONENT**

Catalog Number	No. of Grooves	P.D.	O.D.	F.D. ± 1/64	B Bore +.001 -0.000	E Length ± 1/64	C Hub Dia. ± 1/64	D Hub Proj.	Set Screw
A 6A 3-10DF02506	10	.637	.617	7/8	.1875	11/16	3/8	1/4	#6-40
A 6A 3-11DF02506	11	.700	.680	15/16	.1875	11/16	7/16	1/4	#6-40
A 6A 3-11DF02508	11	.700	.680	15/16	.250	11/16	7/16	1/4	#8-32
A 6A 3-12DF02506	12	.764	.744	1	.1875	11/16	1/2	1/4	#6-40
A 6A 3-12DF02508	12	.764	.744	1	.250	11/16	1/2	1/4	#8-32
A 6A 3-13DF02508	13	.828	.808	1-1/16	.250	11/16	9/16	1/4	#8-32
A 6A 3-14DF02508	14	.891	.871	1-3/32	.250	11/16	9/16	1/4	#8-32
A 6A 3-14DF02510	14	.891	.871	1-3/32	.3125	11/16	9/16	1/4	#8-32
A 6A 3-15DF02508	15	.955	.935	1-3/16	.250	11/16	5/8	1/4	#8-32
A 6A 3-15DF02510	15	.955	.935	1-3/16	.3125	11/16	5/8	1/4	#8-32
A 6A 3-16DF02508	16	1.019	.999	1-1/4	.250	11/16	11/16	1/4	#8-32
A 6A 3-16DF02510	16	1.019	.999	1-1/4	.3125	11/16	11/16	1/4	#8-32
A 6A 3-18DF02508	18	1.146	1.126	1-3/8	.250	11/16	13/16	1/4	#8-32
A 6A 3-18DF02510	18	1.146	1.126	1-3/8	.3125	11/16	13/16	1/4	#8-32
A 6A 3-20DF02508	20	1.273	1.253	1-1/2	.250	3/4	15/16	5/16	#8-32
A 6A 3-20DF02510	20	1.273	1.253	1-1/2	.3125	3/4	15/16	5/16	#8-32
A 6A 3-21DF02508	21	1.337	1.317	1-9/16	.250	3/4	1	5/16	#8-32
A 6A 3-21DF02510	21	1.337	1.317	1-9/16	.3125	3/4	1	5/16	#8-32
A 6A 3-22DF02508	22	1.401	1.381	1-5/8	.250	3/4	1	5/16	#8-32
A 6A 3-22DF02512	22	1.401	1.381	1-5/8	.375	3/4	1	5/16	#10-32
A 6A 3-24DF02508	24	1.528	1.508	1-3/4	.250	25/32	1-1/16	11/32	#8-32
A 6A 3-24DF02510	24	1.528	1.508	1-3/4	.3125	25/32	1-1/16	11/32	#8-32
A 6A 3-24DF02512	24	1.528	1.508	1-3/4	.375	25/32	1-1/16	11/32	#10-32
A 6A 3-26DF02508	26	1.655	1.635	1-7/8	.250	25/32	1-3/16	11/32	#8-32
A 6A 3-26DF02512	26	1.655	1.635	1-7/8	.375	25/32	1-3/16	11/32	#10-32
A 6A 3-28DF02508	28	1.783	1.763	2	.250	25/32	1-3/16	11/32	#8-32
A 6A 3-28DF02512	28	1.783	1.763	2	.375	25/32	1-3/16	11/32	#10-32
A 6A 3-30DF02508	30	1.910	1.890	2-1/8	.250	25/32	1-5/16	11/32	#8-32
A 6A 3-30DF02512	30	1.910	1.890	2-1/8	.375	25/32	1-5/16	11/32	#10-32