

**FOR 3/8" BELTS**  
DOUBLE FLANGE


PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

**> MATERIAL:**  
Aluminum Alloy

**> FINISH:**  
Clear Anodized

**> SPECIFICATIONS:**  
O.D. Tolerance: 10 to 16 grooves is  $+.002/-0.000$   
17 to 20 grooves is  $+.003/-0.000$

Pulleys with 10 & 11 grooves have 1 set screw;  
others have 2 set screws at 90°.

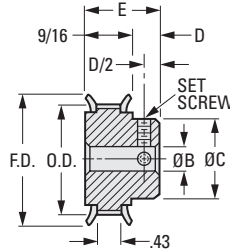

**INCH COMPONENT**

Catalog Number	No. of Grooves	P.D.	O.D.	F.D. ± 1/64	B Bore +.001 - .000	E Length ± 1/64	C Hub Dia. ± 1/64	D Hub Proj.	Set Screw
A 6A 3-10DF03706	10	.637	.617	7/8	.1875	13/16	7/16	1/4	#6-40
A 6A 3-10DF03708	10	.637	.617	7/8	.250	13/16	7/16	1/4	#8-32
A 6A 3-11DF03706	11	.700	.680	15/16	.1875	13/16	1/2	1/4	#6-40
A 6A 3-11DF03708	11	.700	.680	15/16	.250	13/16	1/2	1/4	#8-32
A 6A 3-12DF03706	12	.764	.744	1	.1875	13/16	1/2	1/4	#6-40
A 6A 3-12DF03708	12	.764	.744	1	.250	13/16	1/2	1/4	#8-32
A 6A 3-12DF03710	12	.764	.744	1	.3125	13/16	1/2	1/4	#8-32
A 6A 3-13DF03708	13	.828	.808	1-1/16	.250	13/16	9/16	1/4	#8-32
A 6A 3-14DF03708	14	.891	.871	1-3/32	.250	13/16	9/16	1/4	#8-32
A 6A 3-14DF03710	14	.891	.871	1-3/32	.3125	13/16	9/16	1/4	#8-32
A 6A 3-15DF03708	15	.955	.935	1-3/16	.250	13/16	5/8	1/4	#8-32
A 6A 3-15DF03710	15	.955	.935	1-3/16	.3125	13/16	5/8	1/4	#8-32
A 6A 3-15DF03712	15	.955	.935	1-3/16	.375	13/16	3/4	1/4	#8-32
A 6A 3-15DF03716	15	.955	.935	1-3/16	.500	13/16	3/4	1/4	#8-32
A 6A 3-16DF03708	16	1.019	.999	1-1/4	.250	13/16	11/16	1/4	#8-32
A 6A 3-16DF03710	16	1.019	.999	1-1/4	.3125	13/16	11/16	1/4	#8-32
A 6A 3-16DF03712	16	1.019	.999	1-1/4	.375	13/16	11/16	1/4	#8-32
A 6A 3-17DF03708	17	1.082	1.062	1-5/16	.250	13/16	3/4	1/4	#8-32
A 6A 3-18DF03708	18	1.146	1.126	1-3/8	.250	13/16	13/16	1/4	#8-32
A 6A 3-18DF03710	18	1.146	1.126	1-3/8	.3125	13/16	13/16	1/4	#8-32
A 6A 3-18DF03712	18	1.146	1.126	1-3/8	.375	13/16	13/16	1/4	#8-32
A 6A 3-19DF03708	19	1.210	1.190	1-7/16	.250	13/16	7/8	1/4	#8-32
A 6A 3-20DF03708	20	1.273	1.253	1-1/2	.250	7/8	15/16	5/16	#8-32
A 6A 3-20DF03710	20	1.273	1.253	1-1/2	.3125	7/8	15/16	5/16	#8-32
A 6A 3-20DF03712	20	1.273	1.253	1-1/2	.375	7/8	15/16	5/16	#10-32
A 6A 3-20DF03716	20	1.273	1.253	1-1/2	.500	7/8	15/16	5/16	#10-32

Continued on the next page

**FOR 3/8" BELTS**  
DOUBLE FLANGE


PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

**> MATERIAL:**  
Aluminum Alloy

**> FINISH:**  
Clear Anodized

**> SPECIFICATIONS:**  
O.D. Tolerance: 21 to 30 grooves is  $+.003/-0.00$   
32 grooves is  $+.004/-0.00$

All pulleys have 2 set screws at 90°.

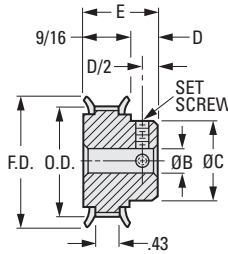

**INCH COMPONENT**

Catalog Number	No. of Grooves	P.D.	O.D.	F.D. ± 1/64	B Bore +.001 -0.000	E Length ± 1/64	C Hub Dia. ± 1/64	D Hub Proj.	Set Screw
A 6A 3-21DF03708	21	1.337	1.317	1-9/16	.250	7/8	1	5/16	#8-32
A 6A 3-21DF03710	21	1.337	1.317	1-9/16	.3125	7/8	1	5/16	#8-32
A 6A 3-21DF03712	21	1.337	1.317	1-9/16	.375	7/8	1	5/16	#10-32
A 6A 3-22DF03708	22	1.401	1.381	1-5/8	.250	7/8	1	5/16	#8-32
A 6A 3-22DF03710	22	1.401	1.381	1-5/8	.3125	7/8	1	5/16	#8-32
A 6A 3-22DF03712	22	1.401	1.381	1-5/8	.375	7/8	1	5/16	#10-32
A 6A 3-23DF03708	23	1.464	1.444	1-11/16	.250	7/8	1-1/16	5/16	#8-32
A 6A 3-24DF03708	24	1.528	1.508	1-3/4	.250	29/32	1-1/16	11/32	#8-32
A 6A 3-24DF03710	24	1.528	1.508	1-3/4	.3125	29/32	1-1/16	11/32	#8-32
A 6A 3-24DF03712	24	1.528	1.508	1-3/4	.375	29/32	1-1/16	11/32	#10-32
A 6A 3-24DF03716	24	1.528	1.508	1-3/4	.500	29/32	1-1/16	11/32	#10-32
A 6A 3-25DF03708	25	1.592	1.572	1-13/16	.250	29/32	1-3/32	11/32	#8-32
A 6A 3-25DF03712	25	1.592	1.572	1-13/16	.375	29/32	1-3/32	11/32	#10-32
A 6A 3-26DF03708	26	1.655	1.635	1-7/8	.250	29/32	1-3/16	11/32	#8-32
A 6A 3-26DF03712	26	1.655	1.635	1-7/8	.375	29/32	1-3/16	11/32	#10-32
A 6A 3-28DF03708	28	1.783	1.763	2	.250	29/32	1-3/16	11/32	#8-32
A 6A 3-28DF03710	28	1.783	1.763	2	.3125	29/32	1-3/16	11/32	#8-32
A 6A 3-28DF03712	28	1.783	1.763	2	.375	29/32	1-3/16	11/32	#10-32
A 6A 3-30DF03708	30	1.910	1.890	2-1/8	.250	29/32	1-5/16	11/32	#8-32
A 6A 3-30DF03710	30	1.910	1.890	2-1/8	.3125	29/32	1-5/16	11/32	#8-32
A 6A 3-30DF03712	30	1.910	1.890	2-1/8	.375	29/32	1-5/16	11/32	#10-32
A 6A 3-30DF03716	30	1.910	1.890	2-1/8	.500	29/32	1-5/16	11/32	#10-32
A 6A 3-32DF03712	32	2.037	2.017	2-1/4	.375	29/32	1-7/16	11/32	#10-32

Continued from the previous page