

**FOR 3/8" BELTS**  
DOUBLE FLANGE


PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

► **MATERIAL:**  
Steel

► **FINISH:**  
Black Oxide

► **SPECIFICATIONS:**  
O.D. Tolerance: 10 to 16 grooves is  $\pm .002/- .000$   
18 & 20 grooves is  $\pm .003/- .000$

Pulleys with 10 & 11 grooves have 1 set screw;  
others have 2 set screws at 90°.

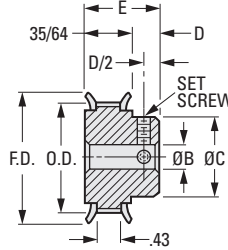

**INCH COMPONENT**

Catalog Number	No. of Grooves	P.D.	O.D.	F.D.	B Bore $\pm .001$ $- .000$	E Length $\pm 1/64$	C Hub Dia. $\pm 1/64$	D Hub Proj.	Set Screw
A 6C 3-10DF03706	10	.637	.617	7/8	.1875	13/16	7/16	17/64	#6-40
A 6C 3-10DF03708	10	.637	.617	7/8	.250	13/16	7/16	17/64	#8-32
A 6C 3-11DF03706	11	.700	.680	15/16	.1875	13/16	1/2	17/64	#6-40
A 6C 3-11DF03708	11	.700	.680	15/16	.250	13/16	1/2	17/64	#8-32
A 6C 3-12DF03706	12	.764	.744	1	.1875	13/16	1/2	17/64	#6-40
A 6C 3-12DF03708	12	.764	.744	1	.250	13/16	1/2	17/64	#8-32
A 6C 3-12DF03710	12	.764	.744	1	.3125	13/16	1/2	17/64	#8-32
A 6C 3-14DF03708	14	.891	.871	1-3/32	.250	13/16	9/16	17/64	#8-32
A 6C 3-14DF03710	14	.891	.871	1-3/32	.3125	13/16	9/16	17/64	#8-32
A 6C 3-15DF03708	15	.955	.935	1-3/16	.250	13/16	5/8	17/64	#8-32
A 6C 3-15DF03710	15	.955	.935	1-3/16	.3125	13/16	5/8	17/64	#8-32
A 6C 3-15DF03712	15	.955	.935	1-3/16	.375	13/16	3/4	17/64	#8-32
A 6C 3-15DF03716	15	.955	.935	1-3/16	.500	13/16	3/4	17/64	#8-32
A 6C 3-16DF03708	16	1.019	.999	1-1/4	.250	13/16	11/16	17/64	#8-32
A 6C 3-16DF03710	16	1.019	.999	1-1/4	.3125	13/16	11/16	17/64	#8-32
A 6C 3-18DF03708	18	1.146	1.126	1-3/8	.250	13/16	13/16	17/64	#8-32
A 6C 3-18DF03710	18	1.146	1.126	1-3/8	.3125	13/16	13/16	17/64	#8-32
A 6C 3-18DF03712	18	1.146	1.126	1-3/8	.375	13/16	13/16	17/64	#8-32
A 6C 3-20DF03708	20	1.273	1.253	1-1/2	.250	7/8	15/16	21/64	#8-32
A 6C 3-20DF03710	20	1.273	1.253	1-1/2	.3125	7/8	15/16	21/64	#8-32
A 6C 3-20DF03712	20	1.273	1.253	1-1/2	.375	7/8	15/16	21/64	#10-32
A 6C 3-20DF03716	20	1.273	1.253	1-1/2	.500	7/8	15/16	21/64	#10-32

Continued on the next page