

FOR 1/2" BELTS  
DOUBLE FLANGE

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

➤ MATERIAL:

Aluminum Alloy


➤ FINISH:

Clear Anodized

➤ SPECIFICATIONS:

O.D. Tolerance:  
10 to 17 grooves is +.003/-0.000  
18 to 24 grooves is +.004/-0.000

Pulleys supplied with 2 set screws at 90°.

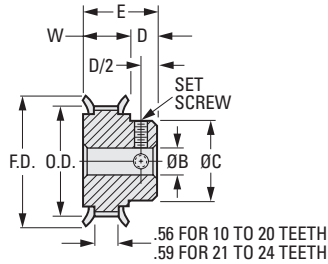

**INCH COMPONENT**

Catalog Number	No. of Grooves	P.D.	O.D.	F.D. ± 1/64	B Bore +.001 -.000	W Body	E Length ± 1/64	C Hub Dia. ± 1/64	D Hub Proj.	Set Screw
A 6A 4-10DF05012	10	1.194	1.164	1-7/16	.375	23/32	1-1/8	7/8	13/32	#10-32
A 6A 4-10DF05016	10	1.194	1.164	1-7/16	.500	23/32	1-1/8	7/8	13/32	1/4-20
A 6A 4-11DF05012	11	1.313	1.283	1-17/32	.375	23/32	1-1/8	1	13/32	#10-32
A 6A 4-11DF05016	11	1.313	1.283	1-17/32	.500	23/32	1-1/8	1	13/32	1/4-20
A 6A 4-12DF05012	12	1.432	1.402	1-21/32	.375	23/32	1-3/16	1-1/8	15/32	#10-32
A 6A 4-12DF05016	12	1.432	1.402	1-21/32	.500	23/32	1-3/16	1-1/8	15/32	1/4-20
A 6A 4-13DF05012	13	1.552	1.522	1-25/32	.375	23/32	1-3/16	1-1/8	15/32	#10-32
A 6A 4-13DF05016	13	1.552	1.522	1-25/32	.500	23/32	1-3/16	1-1/8	15/32	1/4-20
A 6A 4-14DF05012	14	1.671	1.641	1-29/32	.375	23/32	1-3/16	1-1/4	15/32	#10-32
A 6A 4-14DF05016	14	1.671	1.641	1-29/32	.500	23/32	1-3/16	1-1/4	15/32	1/4-20
A 6A 4-15DF05012	15	1.790	1.760	2-1/32	.375	23/32	1-1/4	1-3/8	17/32	#10-32
A 6A 4-15DF05016	15	1.790	1.760	2-1/32	.500	23/32	1-1/4	1-3/8	17/32	1/4-20
A 6A 4-16DF05016	16	1.910	1.880	2-1/8	.500	23/32	1-1/4	1-3/8	17/32	1/4-20
A 6A 4-16DF05020	16	1.910	1.880	2-1/8	.625	23/32	1-1/4	1-3/8	17/32	1/4-20
A 6A 4-17DF05016	17	2.029	1.999	2-1/4	.500	23/32	1-1/4	1-1/2	17/32	1/4-20
A 6A 4-17DF05020	17	2.029	1.999	2-1/4	.625	23/32	1-1/4	1-1/2	17/32	1/4-20
A 6A 4-18DF05016	18	2.149	2.119	2-3/8	.500	23/32	1-1/4	1-5/8	17/32	1/4-20
A 6A 4-18DF05020	18	2.149	2.119	2-3/8	.625	23/32	1-1/4	1-5/8	17/32	1/4-20
A 6A 4-19DF05016	19	2.268	2.238	2-1/2	.500	23/32	1-5/16	1-11/16	19/32	1/4-20
A 6A 4-19DF05020	19	2.268	2.238	2-1/2	.625	23/32	1-5/16	1-11/16	19/32	1/4-20
A 6A 4-20DF05016	20	2.387	2.357	2-5/8	.500	23/32	1-5/16	1-13/16	19/32	1/4-20
A 6A 4-20DF05020	20	2.387	2.357	2-5/8	.625	23/32	1-5/16	1-13/16	19/32	1/4-20
A 6A 4-21DF05016	21	2.507	2.477	2-3/4	.500	3/4	1/3-8	2	5/8	1/4-20
A 6A 4-21DF05020	21	2.507	2.477	2-3/4	.625	3/4	1/3-8	2	5/8	1/4-20
A 6A 4-22DF05016	22	2.626	2.596	2-7/8	.500	3/4	1/3-8	2-1/8	5/8	1/4-20
A 6A 4-22DF05020	22	2.626	2.596	2-7/8	.625	3/4	1/3-8	2-1/8	5/8	1/4-20
A 6A 4-24DF05016	24	2.865	2.835	3-3/32	.500	3/4	1/3-8	2-1/4	5/8	1/4-20
A 6A 4-24DF05020	24	2.865	2.835	3-3/32	.625	3/4	1/3-8	2-1/4	5/8	1/4-20