

FOR 3/4" BELTS
 MOLDED WITH METAL INSERT
 SINGLE OR DOUBLE FLANGE

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM



MATERIAL:

Pulley - Polycarbonate, Fiberglass Reinforced
Insert - Aluminum, Knurled

SPECIFICATIONS:

Pulleys with 10 to 16 grooves do not have webs.
 All Pulleys have 2 set screws at 90°.

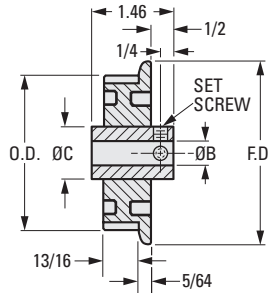
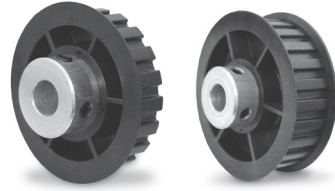


Fig. 1

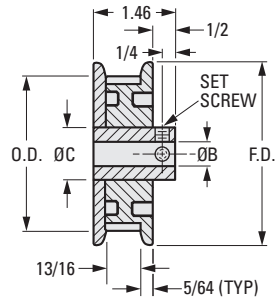


Fig. 2

INCH COMPONENT

Catalog Number		No. of Grooves	P.D.	O.D.	F.D.	B Bore +.001 - .000	C Hub Dia.	Set Screw
Fig. 1 Single Flange	Fig. 2 Double Flange							
A 6Z 4-10SF07512	A 6Z 4-10DF07512	10	1.194	1.164	1.44	.375	7/8	#10-32
A 6Z 4-10SF07516	A 6Z 4-10DF07516	10	1.194	1.164	1.44	.500	7/8	#10-32
A 6Z 4-12SF07512	A 6Z 4-12DF07512	12	1.432	1.402	1.69	.375	7/8	#10-32
A 6Z 4-12SF07516	A 6Z 4-12DF07516	12	1.432	1.402	1.69	.500	7/8	#10-32
A 6Z 4-16SF07516	A 6Z 4-16DF07516	16	1.910	1.880	2.12	.500	1-1/8	1/4-28
A 6Z 4-16SF07520	A 6Z 4-16DF07520	16	1.910	1.880	2.12	.625	1-1/8	1/4-28
A 6Z 4-18SF07516	A 6Z 4-18DF07516	18	2.149	2.119	2.37	.500	1-1/8	1/4-28
A 6Z 4-18SF07520	A 6Z 4-18DF07520	18	2.149	2.119	2.37	.625	1-1/8	1/4-28
A 6Z 4-20SF07516	A 6Z 4-20DF07516	20	2.387	2.357	2.62	.500	1-1/8	1/4-28
A 6Z 4-20SF07520	A 6Z 4-20DF07520	20	2.387	2.357	2.62	.625	1-1/8	1/4-28
A 6Z 4-24SF07516	A 6Z 4-24DF07516	24	2.865	2.835	3.12	.500	1-1/8	1/4-28
A 6Z 4-24SF07520	A 6Z 4-24DF07520	24	2.865	2.835	3.12	.625	1-1/8	1/4-28
A 6Z 4-36SF07516	A 6Z 4-36DF07516	36	4.297	4.267	4.53	.500	1-1/8	1/4-28
A 6Z 4-36SF07520	A 6Z 4-36DF07520	36	4.297	4.267	4.53	.625	1-1/8	1/4-28
A 6Z 4-40SF07516	A 6Z 4-40DF07516	40	4.775	4.745	5.00	.500	1-1/8	1/4-28
A 6Z 4-40SF07520	A 6Z 4-40DF07520	40	4.775	4.745	5.00	.625	1-1/8	1/4-28