

MINIATURE ROLLER CHAINS • .1475 PITCH



SINGLE STRAND
RIVETED

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

› **MATERIAL:**
Stainless Steel Type 18-8

› **FINISH:**
Clear Passivated

› **AVERAGE TENSILE LOAD:**
175 lbf

› **SPECIFICATION:**
All lengths include and are supplied with connecting link A 6Y 7-14CHA


› **WEIGHT:**
.035 lbs per foot

Sizes not listed are available on special request.



| | |
|------------------------------------|--------------|
| CONNECTING LINK (SNAP TYPE) | |
| Catalog Number | A 6Y 7-14CHA |

| | |
|-----------------------|-------------|
| BUSHING LINK | |
| Catalog Number | A 6Y 7-14BL |

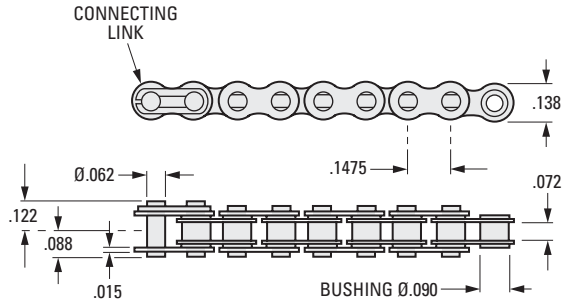

INCH COMPONENT

| Catalog Number | No. of Links | Length |
|----------------|--------------|--------|
| A 6Y 7-M040 | 40 | 5.900 |
| A 6Y 7-M050 | 50 | 7.375 |
| A 6Y 7-M060 | 60 | 8.850 |
| A 6Y 7-M070 | 70 | 10.325 |
| A 6Y 7-M080 | 80 | 11.800 |
| A 6Y 7-M090 | 90 | 13.275 |
| A 6Y 7-M100 | 100 | 14.750 |
| A 6Y 7-M110 | 110 | 16.225 |
| A 6Y 7-M120 | 120 | 17.700 |
| A 6Y 7-M130 | 130 | 19.175 |
| A 6Y 7-M140 | 140 | 20.650 |
| A 6Y 7-M150 | 150 | 22.125 |
| A 6Y 7-M160 | 160 | 23.600 |
| A 6Y 7-M170 | 170 | 25.075 |
| A 6Y 7-M180 | 180 | 26.550 |
| A 6Y 7-M190 | 190 | 28.025 |
| A 6Y 7-M200 | 200 | 29.500 |
| A 6Y 7-M210 | 210 | 30.975 |
| A 6Y 7-M220 | 220 | 32.450 |
| A 6Y 7-M230 | 230 | 33.925 |
| A 6Y 7-M240 | 240 | 35.400 |