

NO. 25 SINGLE STRAND CHAINS
MOLDED
.110 FACE


PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

> MATERIAL:

Molded Nylon, Fiberglass Reinforced

> SPECIFICATION:

All these sprockets can be used with #25, 1/4 pitch roller or ladder chains.

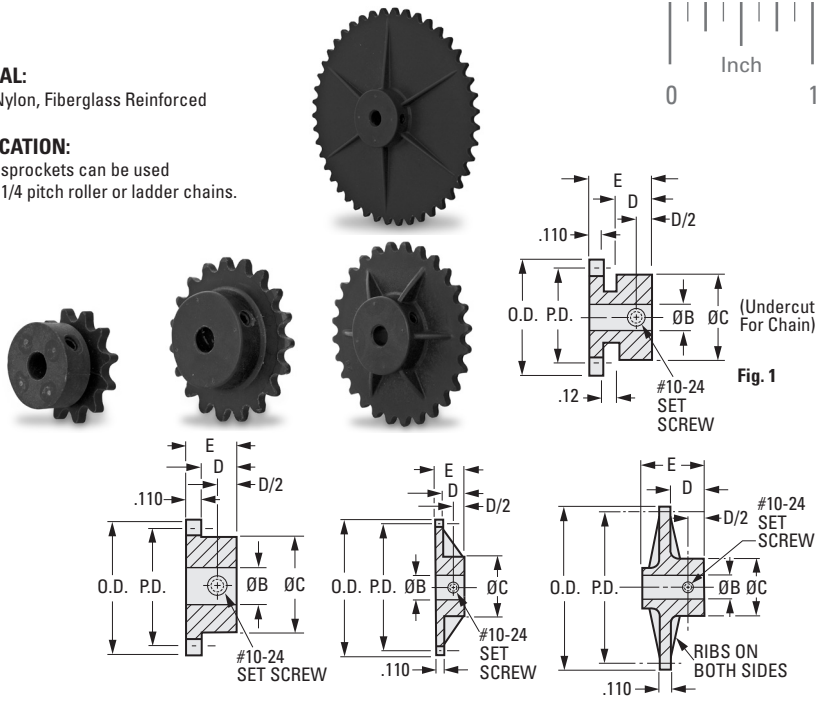

INCH COMPONENT

Catalog Number	No. of Teeth	P.D.	O.D.	B Bore +.0015 -.0000	E Length	C Hub Dia.	D Hub Proj.
Fig. 1							
A 6T 7-2509	9	.731	.850	.2505	35/64	13/16	5/16
A 6T 7-2510	10	.809	.931	.2505	35/64	13/16	5/16
A 6T 7-2511	11	.887	1.010	.2505	35/64	13/16	5/16
A 6T 7-2512	12	.966	1.092	.2505	35/64	13/16	5/16
A 6T 7-2513	13	1.044	1.170	.2505	35/64	13/16	5/16
Fig. 2							
A 6T 7-2514	14	1.123	1.250	.2505	27/64	13/16	5/16
A 6T 7-2515	15	1.202	1.332	.2505	27/64	13/16	5/16
Fig. 3							
A 6T 7-2516	16	1.281	1.412	.2505	27/64	1	5/16
A 6T 7-2517	17	1.360	1.493	.2505	27/64	1	5/16
A 6T 7-2518	18	1.439	1.573	.2505	27/64	1	5/16
A 6T 7-2519	19	1.519	1.654	.2505	27/64	1	5/16
A 6T 7-2520	20	1.598	1.731	.2505	27/64	1	5/16
A 6T 7-2521	21	1.677	1.813	.2505	27/64	1	5/16
A 6T 7-2522	22	1.757	1.892	.2505	27/64	1	5/16
A 6T 7-2524	24	1.915	2.052	.2505	27/64	1	5/16
A 6T 7-2526	26	2.074	2.214	.2505	27/64	1	5/16
A 6T 7-2528	28	2.233	2.368	.2505	27/64	1	5/16
A 6T 7-2530	30	2.392	2.529	.2505	27/64	1	5/16
Fig. 4							
A 6T 7-2532	32	2.550	2.686	.2505	37/64	1	5/16
A 6T 7-2536	36	2.868	3.003	.2505	37/64	1	5/16
A 6T 7-2540	40	3.186	3.319	.2505	37/64	1	5/16
A 6T 7-2545	45	3.583	3.716	.2505	37/64	1	5/16
A 6T 7-2548	48	3.822	3.955	.2505	37/64	1	5/16

