


FOR 1/4" FLAT BELTS  
MOLDED WITH INSERT  
MACHINED O.D.



PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

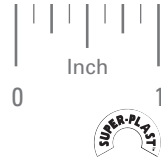

**> MATERIAL:**

- Pulley** - Polycarbonate, Fiberglass Reinforced
- Insert** - Aluminum, Knurled - Clear Anodized
- Brass, Knurled

Pulleys with nonstandard diameters or of special design are available custom-made to your drawings.

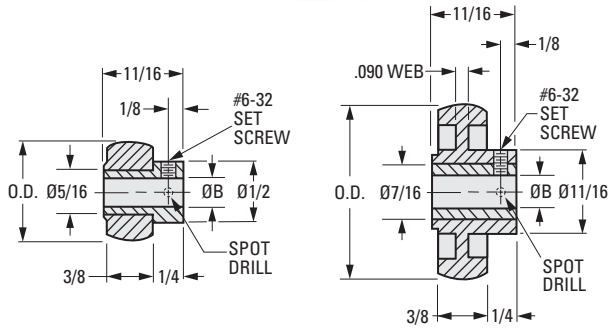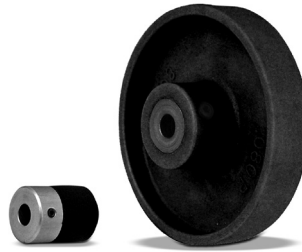

**Fig. 1**  
Aluminum Insert

**Fig. 2**  
Brass Insert

**INCH COMPONENT**

Catalog Number	O.D.		B Bore +.001 -.000
	mm	Inch	
<b>Fig. 1</b>			
A 6T19-132506	13	.512	.1875
A 6T19-132508	13	.512	.250
A 6T19-152506	15	.591	.1875
A 6T19-152508	15	.591	.250
A 6T19-172506	17	.669	.1875
A 6T19-172508	17	.669	.250
A 6T19-182506	18	.709	.1875
A 6T19-182508	18	.709	.250
A 6T19-202506	20	.787	.1875
A 6T19-202508	20	.787	.250
<b>Fig. 2</b>			
A 6T19-232506	23	.906	.1875
A 6T19-232508	23	.906	.250
A 6T19-242506	24	.945	.1875
A 6T19-242508	24	.945	.250
A 6T19-262506	26	1.024	.1875
A 6T19-262508	26	1.024	.250
A 6T19-282506	28	1.102	.1875
A 6T19-282508	28	1.102	.250

Catalog Number	O.D.		B Bore +.001 -.000
	mm	Inch	
<b>Fig. 2</b>			
A 6T19-362506	36	1.417	.1875
A 6T19-362508	36	1.417	.250
A 6T19-392506	39	1.535	.1875
A 6T19-392508	39	1.535	.250
A 6T19-442506	44	1.732	.1875
A 6T19-442508	44	1.732	.250
A 6T19-492506	49	1.929	.1875
A 6T19-492508	49	1.929	.250
A 6T19-552506	55	2.165	.1875
A 6T19-552508	55	2.165	.250
A 6T19-622506	62	2.441	.1875
A 6T19-622508	62	2.441	.250
A 6T19-682506	68	2.677	.1875
A 6T19-682508	68	2.677	.250
A 6T19-752506	75	2.953	.1875
A 6T19-752508	75	2.953	.250
A 6T19-812506	81	3.189	.1875
A 6T19-812508	81	3.189	.250

