

# SET SCREW COLLARS



WITH INTEGRAL BEARING SHIM SPACER



PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

**> MATERIAL:**

303 Stainless Steel

**> FEATURES:**

No shim spacers required.  
Used to preload bearing.

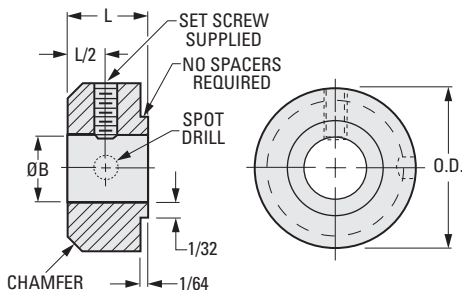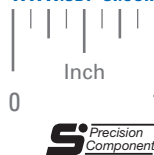

## INCH COMPONENT

Catalog Number	Shaft Size	O.D.	B Bore +.0005 -.0000	L	Set Screw	Spot Drill
S25CY9-PC0608	3/32	1/4	.0935	.120	#0-80	#78 (.016)
S25CY9-PC0810	1/8	5/16	.1248	.180	#2-56	#69 (.028)
S25CY9-PC1010	5/32	5/16	.1560	.180	#2-56	#69 (.028)
S25CY9-PC1212	3/16	3/8	.1873	.220	#4-40	#60 (.040)
S25CY9-PC1516	.2405	1/2	.2405	.250	#6-32	#50 (.070)
S25CY9-PC1616	1/4	1/2	.2498	.250	#6-32	#50 (.070)
S25CY9-PC2016	5/16	1/2	.3123	.250	#6-32	#50 (.070)
S25CY9-PC2424	3/8	3/4	.3748	.375	#10-24	#31 (.120)
S25CY9-PC3232	1/2	1	.4998	.437	1/4-20	#25 (.149)
S25CY9-PC4040	5/8	1-1/4	.6248	.500	1/4-20	#25 (.149)
S25CY9-PC4848	3/4	1-1/2	.7498	.562	3/8-16	#22 (.157)
S25CY9-PC6464	1	2	.9998	.625	3/8-16	#22 (.157)
S25CY9-PC8072	1-1/4	2-1/4	1.2498	.750	3/8-16	#22 (.157)

1

R

T

1

2

3

4

5

6

7

8

9

10

11

12

13

14

15

16