


> MATERIAL:

Oil-Impregnated Bronze, Self-Lubricating

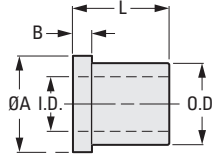

INCH COMPONENT

Catalog Number	I.D. +.001 -.000	O.D. +.000 -.001	L Length ± .005 *	A Flange Dia. ± .005	B Flange Width
A 7B 4-F042	.1245	.2215	.122 – .115	.340	.050 – .048
A 7B 4-F048	.125	.190	.228 – .216	.250	.035 – .031
A 7B 4-F063	.126	.2215	.148 – .141	.345	.061 – .057
A 7B 4-F043	.1875	.284	.218 – .212	.375	.057 – .052
A 7B 4-F040		.3155	.1345 – .1265	.437	.064 – .060
A 7B 4-F103		.253	.349 – .344	.310	.034 – .031
A 7B 4-F002	.188	.2843	.281	.375	.121 – .117
A 7B 4-F102		.3155	.240 – .234	.437	.087 – .081
A 7B 4-F027		.316	.375	.437	.064 – .060
A 7B 4-F054	.218	.2825	.207 – .202	.310	.084 – .079
A 7B 4-F078		.3155	.500	.437	.066 – .058
A 7B 4-F004	.251	.316	.156	.437	.065 – .059
A 7B 4-F106			.250		
A 7B 4-F006			.406		
A 7B 4-F050		.379	.578 – .573	.500	.095 – .093
A 7B 4-F007	.281		.2188		
A 7B 4-F008	.3125		.4848		
A 7B 4-F010	.375	.504	.404	.562	.065 – .059
A 7B 4-F053			.696 – .690		
A 7B 4-F074	.376	.566	.660	.750	.093 – .090
△ A 7B 4-F014	.377	.629	.610 – .611	.875	.063 – .060
A 7B 4-F016		.504	.154 – .149	.562	.077 – .072
A 7B 4-F068	.438	.5655	.281	.781	.065 – .060
A 7B 4-F057			.546		
A 7B 4-F041	.500	.628	.198 – .192	.870	.042 – .040
A 7B 4-F085			.139 – .136	.875	.050 – .044
A 7B 4-F017		.629	.250	.812	.095 – .091
A 7B 4-F067	.501		.307		.065 – .059
A 7B 4-F018			.562		
A 7B 4-F026		.754	.515	.875	.145 – .140
A 7B 4-F021			.969		.060 – .057
A 7B 4-F065			.230		.145 – .140
A 7B 4-F055	.626	.7535	.371	.991	.063 – .059
A 7B 4-F082			.630		

* Unless otherwise specified.

△ To be discontinued when present stock is depleted.