

TELESCOPING UNIVERSAL JOINTS

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM


HEAT-RESISTANT
CORROSION-RESISTANT



> MATERIAL:

Joints - 303 Series Stainless Steel
Spline - 416 Stainless Steel

> OPERATING TEMPERATURE:
0°F to +750°F

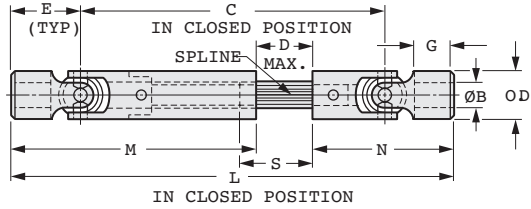

INCH COMPONENT

Catalog Number	O.D.	B Bore +.001 -.000	E	M	N	L Closed	C Closed	D Max.	Max. Torque lbf. in.	S	G
A 5X 8-SE1608	1/2	.250	.79	3.83	1.58	5.41	3.83	1-5/8	40	2-1/4	33/64
A 5X 8-SE2012	5/8	.375	.98	4.96	1.96	6.92	4.96	2-1/4	95	3	21/32
A 5X 8-SE2514	25/32	.4375	1.10	5.95	2.20	8.15	5.95	2-7/8	240	3-3/4	43/64
A 5X 8-SE3216	1	.500	1.40	7.30	2.80	10.10	7.30	3-1/4	600	4-1/2	55/64
A 5X 8-SE3220		.625									


NOTE: Total open length = L (Closed) + D (Max).

UNIVERSAL JOINTS

DOUBLE JOINT
HAND-OPERATED & POWER DRIVEN
1750 rpm OR LESS



> MATERIAL:
Alloy Steel

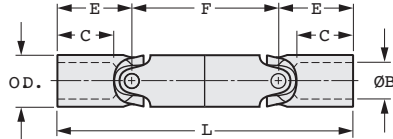

INCH COMPONENT

Catalog Number	O.D.	B Bore +.001 -.000	C Bore Depth ± 1/32	L Overall Length	E	F	Approx. Weight lb.
Solid							
A 5Q 8-DD100	3/8	—	—	3-1/2	7/8	1-3/4	.09
A 5Q 8-DD200	1/2			4	1	2	.18
A 5Q 8-DD300	5/8			4-1/2	1-1/8	2-1/4	.32
A 5Q 8-DD400	3/4			5-3/8	1-11/32	2-11/16	.55
A 5Q 8-DD500	7/8			6	1-1/2	3	.82
A 5Q 8-DD600	1			6-3/4	1-11/16	3-3/8	1.20
Bored							
A 5Q 8-DD106	3/8	.1875	9/16	3-1/2	7/8	1-3/4	.08
A 5Q 8-DD208	1/2	.250	5/8	4	1	2	.16
A 5Q 8-DD310	5/8	.3125	11/16	4-1/2	1-1/8	2-1/4	.30
A 5Q 8-DD412	3/4	.375	7/8	5-3/8	1-11/32	2-11/16	.50
A 5Q 8-DD514	7/8	.4375	7/8	6	1-1/2	3	.74
A 5Q 8-DD616	1	.500	1	6-3/4	1-11/16	3-3/8	1.05

