
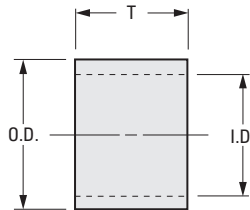


> MATERIAL:

300 Series Stainless Steel

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

Other spacers available on special order.

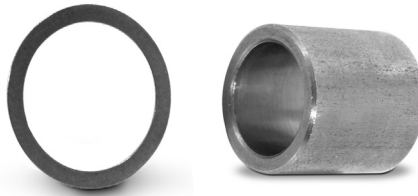

INCH COMPONENT

Catalog Number	I.D.	O.D.	T Thickness
A 7X 8-C04004	1/8	3/16	.004
A 7X 8-C04006	1/8	3/16	.006
A 7X 8-C04008	1/8	3/16	.008
A 7X 8-C04010	1/8	3/16	.010
A 7X 8-C04012	1/8	3/16	.012
A 7X 8-C04014	1/8	3/16	.014
A 7X 8-C04016	1/8	3/16	.016
A 7X 8-C04031	1/8	3/16	.031
A 7X 8-C04063	1/8	3/16	.063
A 7X 8-C04094	1/8	3/16	.094
A 7X 8-C04125	1/8	3/16	.125
A 7X 8-C04188	1/8	3/16	.188
A 7X 8-C04250	1/8	3/16	.250
A 7X 8-C04375	1/8	3/16	.375
A 7X 8-C04500	1/8	3/16	.500
A 7X 8-C06004	3/16	1/4	.004
A 7X 8-C06006	3/16	1/4	.006
A 7X 8-C06008	3/16	1/4	.008
A 7X 8-C06010	3/16	1/4	.010
A 7X 8-C06012	3/16	1/4	.012
A 7X 8-C06014	3/16	1/4	.014
A 7X 8-C06016	3/16	1/4	.016
A 7X 8-C06031	3/16	1/4	.031
A 7X 8-C06063	3/16	1/4	.063
A 7X 8-C06094	3/16	1/4	.094
A 7X 8-C06125	3/16	1/4	.125
A 7X 8-C06188	3/16	1/4	.188

Catalog Number	I.D.	O.D.	T Thickness
A 7X 8-C06250	3/16	1/4	.250
A 7X 8-C06375	3/16	1/4	.375
A 7X 8-C06500	3/16	1/4	.500
A 7X 8-C08004	1/4	3/8	.004
A 7X 8-C08006	1/4	3/8	.006
A 7X 8-C08008	1/4	3/8	.008
A 7X 8-C08010	1/4	3/8	.010
A 7X 8-C08012	1/4	3/8	.012
A 7X 8-C08014	1/4	3/8	.014
A 7X 8-C08016	1/4	3/8	.016
A 7X 8-C08031	1/4	3/8	.031
A 7X 8-C08063	1/4	3/8	.063
A 7X 8-C08094	1/4	3/8	.094
A 7X 8-C08125	1/4	3/8	.125
A 7X 8-C08188	1/4	3/8	.188
A 7X 8-C08250	1/4	3/8	.250
A 7X 8-C08375	1/4	3/8	.375
A 7X 8-C08500	1/4	3/8	.500
A 7X 8-C10004	5/16	7/16	.004
A 7X 8-C10006	5/16	7/16	.006
A 7X 8-C10008	5/16	7/16	.008
A 7X 8-C10010	5/16	7/16	.010
A 7X 8-C10012	5/16	7/16	.012
A 7X 8-C10014	5/16	7/16	.014
A 7X 8-C10016	5/16	7/16	.016
A 7X 8-C10031	5/16	7/16	.031
A 7X 8-C10063	5/16	7/16	.063



Continued on the next page

MATERIAL:

300 Series Stainless Steel

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

Other spacers available on special order.

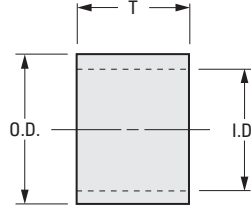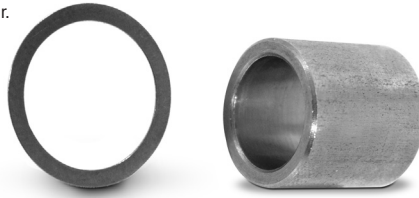

INCH COMPONENT

Catalog Number	I.D.	O.D.	T Thickness
A 7X 8-C10094	5/16	7/16	.094
A 7X 8-C10125	5/16	7/16	.125
A 7X 8-C10188	5/16	7/16	.188
A 7X 8-C10250	5/16	7/16	.250
A 7X 8-C10375	5/16	7/16	.375
A 7X 8-C10500	5/16	7/16	.500
A 7X 8-C12004	3/8	1/2	.004
A 7X 8-C12006	3/8	1/2	.006
A 7X 8-C12008	3/8	1/2	.008
A 7X 8-C12010	3/8	1/2	.010
A 7X 8-C12012	3/8	1/2	.012
A 7X 8-C12014	3/8	1/2	.014
A 7X 8-C12016	3/8	1/2	.016
A 7X 8-C12031	3/8	1/2	.031
A 7X 8-C12063	3/8	1/2	.063
A 7X 8-C12094	3/8	1/2	.094
A 7X 8-C12125	3/8	1/2	.125
A 7X 8-C12188	3/8	1/2	.188
A 7X 8-C12250	3/8	1/2	.250
A 7X 8-C12375	3/8	1/2	.375
A 7X 8-C12500	3/8	1/2	.500
A 7X 8-C14004	7/16	9/16	.004
A 7X 8-C14006	7/16	9/16	.006
A 7X 8-C14008	7/16	9/16	.008
A 7X 8-C14010	7/16	9/16	.010
A 7X 8-C14012	7/16	9/16	.012
A 7X 8-C14014	7/16	9/16	.014

Catalog Number	I.D.	O.D.	T Thickness
A 7X 8-C14016	7/16	9/16	.016
A 7X 8-C14031	7/16	9/16	.031
A 7X 8-C14063	7/16	9/16	.063
A 7X 8-C14094	7/16	9/16	.094
A 7X 8-C14125	7/16	9/16	.125
A 7X 8-C14188	7/16	9/16	.188
A 7X 8-C14250	7/16	9/16	.250
A 7X 8-C14375	7/16	9/16	.375
A 7X 8-C14500	7/16	9/16	.500
A 7X 8-C16004	1/2	5/8	.004
A 7X 8-C16006	1/2	5/8	.006
A 7X 8-C16008	1/2	5/8	.008
A 7X 8-C16010	1/2	5/8	.010
A 7X 8-C16012	1/2	5/8	.012
A 7X 8-C16014	1/2	5/8	.014
A 7X 8-C16016	1/2	5/8	.016
A 7X 8-C16031	1/2	5/8	.031
A 7X 8-C16063	1/2	5/8	.063
A 7X 8-C16094	1/2	5/8	.094
A 7X 8-C16125	1/2	5/8	.125
A 7X 8-C16188	1/2	5/8	.188
A 7X 8-C16250	1/2	5/8	.250
A 7X 8-C16375	1/2	5/8	.375
A 7X 8-C16500	1/2	5/8	.500
A 7X 8-C20050	5/8	3/4	.050
A 7X 8-C24050	3/4	7/8	.050

Continued from the previous page