

CURVED SPRING WASHERS




PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

MATERIAL:

301 Stainless Steel
Spring Steel AISI C1075 Blued

SPECIFICATION:

Priced Per 10 Pieces

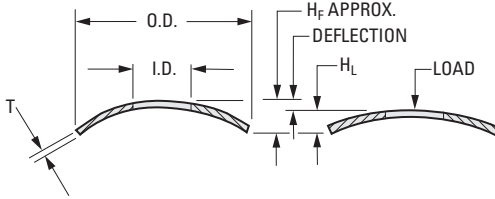

INCH COMPONENT								
Catalog Number		I.D.	O.D.	T Stock Thick.	H _f Free Height	H _l Loaded Height	Load @ H _l ± 15% lbf	For Screw Size
Stainless Steel	Steel							
A 7X 9-1W02406	—	.135	.245	.0060	.034	.020	2.00	#5
A 7X 9-1W02704	—	.148	.270	.0045	.052	.028	1.25	#6
A 7X 9-1W02707	—	.148	.270	.0070	.035	.022	2.50	#6
A 7X 9-1W03205	A 7Q 9-1W03205	.174	.322	.0050	.064	.034	1.50	#8
A 7X 9-1W03207	—	.174	.322	.0075	.042	.025	3.00	#8
A 7X 9-1W03706	—	.200	.370	.0060	.069	.035	2.25	#10
A 7X 9-1W03709	A 7Q 9-1W03709	.200	.370	.0090	.047	.028	4.50	#10
A 7X 9-1W04210	—	.231	.423	.0100	.053	.032	5.00	#12
A 7X 9-1W04907	—	.265	.490	.0075	.091	.046	3.50	1/4
—	A 7Q 9-1W04911	.265	.490	.0110	.063	.034	7.00	1/4
—	A 7Q 9-1W05512	.296	.551	.0120	.070	.038	8.00	9/32
A 7X 9-1W06109	—	.327	.612	.0090	.113	.060	4.50	5/16
A 7X 9-1W06113	A 7Q 9-1W06113	.327	.612	.0130	.077	.042	9.00	5/16
—	A 7Q 9-1W06715	.363	.672	.0150	.081	.047	11.00	11/32
A 7X 9-1W07311	A 7Q 9-1W07311	.395	.735	.0110	.129	.073	6.00	3/8
A 7X 9-1W07316	A 7Q 9-1W07316	.395	.735	.0160	.086	.050	12.00	3/8
A 7X 9-1W08518	A 7Q 9-1W08518	.462	.857	.0180	.100	.057	15.00	7/16
—	A 7Q 9-1W09814	.525	.980	.0140	.164	.083	10.00	1/2
A 7X 9-1W09821	A 7Q 9-1W09821	.525	.980	.0210	.110	.063	20.00	1/2