

STANDARD DOWEL PINS



HARDENED
MS16555

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM




> MATERIAL:

Heat-Treated Type 416 Stainless Steel, Rc 36-42, Clear Passivated

> SPECIFICATION:

Priced Per 100 Pieces

Modifications of standard parts performed at nominal charge.

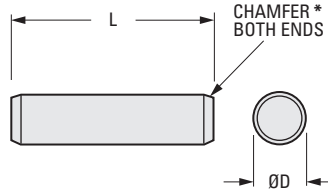

* Chamfer or round ends at SDP option.

INCH COMPONENT

Catalog Number	D Dia. ± .0001	L Length ± .010
A 9Y31-0206	.0627	.188
A 9Y31-0208	.0627	.250
A 9Y31-0210	.0627	.312
A 9Y31-0212	.0627	.375
A 9Y31-0214	.0627	.437
A 9Y31-0216	.0627	.500
A 9Y31-0220	.0627	.625
A 9Y31-0224	.0627	.750
A 9Y31-0310	.0940	.312
A 9Y31-0312	.0940	.375
A 9Y31-0314	.0940	.437
A 9Y31-0316	.0940	.500
A 9Y31-0320	.0940	.625
A 9Y31-0324	.0940	.750
A 9Y31-0328	.0940	.875
A 9Y31-0332	.0940	1.000
A 9Y31-0412	.1252	.375
A 9Y31-0414	.1252	.437
A 9Y31-0416	.1252	.500
A 9Y31-0420	.1252	.625
A 9Y31-0424	.1252	.750
A 9Y31-0428	.1252	.875

Catalog Number	D Dia. ± .0001	L Length ± .010
A 9Y31-0432	.1252	1.000
A 9Y31-0440	.1252	1.250
A 9Y31-0448	.1252	1.500
A 9Y31-0516	.1564	.500
A 9Y31-0520	.1564	.625
A 9Y31-0524	.1564	.750
A 9Y31-0528	.1564	.875
A 9Y31-0532	.1564	1.000
A 9Y31-0540	.1564	1.250
A 9Y31-0620	.1877	.625
A 9Y31-0624	.1877	.750
A 9Y31-0628	.1877	.875
A 9Y31-0632	.1877	1.000
A 9Y31-0640	.1877	1.250
A 9Y31-0648	.1877	1.500
A 9Y31-0824	.2502	.750
A 9Y31-0828	.2502	.875
A 9Y31-0832	.2502	1.000
A 9Y31-0840	.2502	1.250
A 9Y31-0848	.2502	1.500
A 9Y31-0856	.2502	1.750
A 9Y31-0864	.2502	2.000

