

STANDARD DOWEL PINS



PRECISION GROUND
HARDENED
ASME B18.8.2

PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM




› MATERIAL:

Heat-Treated Alloy Steel, Rc 58-62



› SPECIFICATION:

Priced Per 100 Pieces

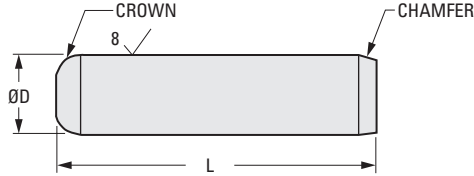

INCH COMPONENT

Catalog Number	D Dia. ± .0001	L Length ± .012
A 9032-0206	.0627	.188
A 9032-0208	.0627	.250
A 9032-0212	.0627	.375
A 9032-0216	.0627	.500
A 9032-0220	.0627	.625
A 9032-0224	.0627	.750
A 9032-0228	.0627	.875
A 9032-0232	.0627	1.000
A 9032-0306	.0940	.188
A 9032-0308	.0940	.250
A 9032-0316	.0940	.500
A 9032-0320	.0940	.625
A 9032-0324	.0940	.750
A 9032-0328	.0940	.875
A 9032-0332	.0940	1.000
A 9032-0412	.1252	.375
A 9032-0416	.1252	.500
A 9032-0420	.1252	.625
A 9032-0424	.1252	.750
A 9032-0428	.1252	.875
A 9032-0432	.1252	1.000
A 9032-0436	.1252	1.125
A 9032-0440	.1252	1.250
A 9032-0444	.1252	1.375
A 9032-0448	.1252	1.500

Catalog Number	D Dia. ± .0001	L Length ± .012
A 9032-0456	.1252	1.750
A 9032-0464	.1252	2.000
A 9032-0616	.1877	.500
A 9032-0624	.1877	.750
A 9032-0628	.1877	.875
A 9032-0632	.1877	1.000
A 9032-0636	.1877	1.125
A 9032-0644	.1877	1.375
A 9032-0648	.1877	1.500
A 9032-0656	.1877	1.750
A 9032-0664	.1877	2.000
A 9032-0816	.2502	.500
A 9032-0820	.2502	.625
A 9032-0824	.2502	.750
A 9032-0828	.2502	.875
A 9032-0832	.2502	1.000
A 9032-0836	.2502	1.125
A 9032-0840	.2502	1.250
A 9032-0844	.2502	1.375
A 9032-0848	.2502	1.500
A 9032-0856	.2502	1.750
A 9032-0864	.2502	2.000
A 9032-0872	.2502	2.250
A 9032-0880	.2502	2.500