

> MATERIAL:


Carbon Steel (Hardened),
Rc Scale 46-53, Oiled Finish



> SPECIFICATION:

Priced Per 100 Pieces

Other lengths and diameters
available on special order.

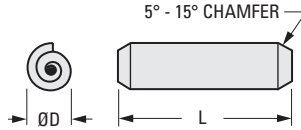

INCH COMPONENT

Catalog Number	D Expanded Dia.		L Length ± .01	Drill Size	
	Min.	Max.		Min.	Max.
*A 9Q36-0104	.033	.035	.125	.031	.032
*A 9Q36-0106	.033	.035	.188	.031	.032
*A 9Q36-0108	.033	.035	.250	.031	.032
*A 9Q36-0110	.033	.035	.312	.031	.032
*A 9Q36-0112	.033	.035	.375	.031	.032
*A 9Q36-0114	.033	.035	.438	.031	.032
*A 9Q36-0116	.033	.035	.500	.031	.032
A 9Q36-0206	.067	.072	.188	.061	.065
A 9Q36-0208	.067	.072	.250	.061	.065
A 9Q36-0210	.067	.072	.312	.061	.065
A 9Q36-0212	.067	.072	.375	.061	.065
A 9Q36-0214	.067	.072	.438	.061	.065
A 9Q36-0216	.067	.072	.500	.061	.065
A 9Q36-0220	.067	.072	.625	.061	.065
A 9Q36-0222	.067	.072	.688	.061	.065
A 9Q36-0224	.067	.072	.750	.061	.065
A 9Q36-0228	.067	.072	.875	.061	.065
A 9Q36-0230	.067	.072	.938	.061	.065
A 9Q36-0232	.067	.072	1.000	.061	.065
A 9Q36-0308	.099	.105	.250	.093	.097
A 9Q36-0310	.099	.105	.312	.093	.097
A 9Q36-0312	.099	.105	.375	.093	.097
A 9Q36-0314	.099	.105	.438	.093	.097
A 9Q36-0316	.099	.105	.500	.093	.097
A 9Q36-0318	.099	.105	.562	.093	.097
A 9Q36-0320	.099	.105	.625	.093	.097
A 9Q36-0322	.099	.105	.688	.093	.097
A 9Q36-0324	.099	.105	.750	.093	.097
A 9Q36-0326	.099	.105	.812	.093	.097
A 9Q36-0328	.099	.105	.875	.093	.097
A 9Q36-0330	.099	.105	.938	.093	.097
A 9Q36-0332	.099	.105	1.000	.093	.097
A 9Q36-0336	.099	.105	1.125	.093	.097
A 9Q36-0340	.099	.105	1.250	.093	.097

Catalog Number	D Expanded Dia.		L Length ± .01	Drill Size	
	Min.	Max.		Min.	Max.
A 9Q36-0410	.131	.138	.312	.124	.129
A 9Q36-0412	.131	.138	.375	.124	.129
A 9Q36-0416	.131	.138	.500	.124	.129
A 9Q36-0418	.131	.138	.562	.124	.129
A 9Q36-0420	.131	.138	.625	.124	.129
A 9Q36-0422	.131	.138	.688	.124	.129
A 9Q36-0424	.131	.138	.750	.124	.129
A 9Q36-0426	.131	.138	.812	.124	.129
A 9Q36-0428	.131	.138	.875	.124	.129
A 9Q36-0430	.131	.138	.938	.124	.129
A 9Q36-0432	.131	.138	1.000	.124	.129
A 9Q36-0436	.131	.138	1.125	.124	.129
A 9Q36-0440	.131	.138	1.250	.124	.129
A 9Q36-0444	.131	.138	1.375	.124	.129
A 9Q36-0448	.131	.138	1.500	.124	.129
A 9Q36-0514	.163	.171	.438	.155	.160
A 9Q36-0516	.163	.171	.500	.155	.160
A 9Q36-0524	.163	.171	.750	.155	.160
A 9Q36-0528	.163	.171	.875	.155	.160
A 9Q36-0532	.163	.171	1.000	.155	.160
A 9Q36-0536	.163	.171	1.125	.155	.160
A 9Q36-0540	.163	.171	1.250	.155	.160
A 9Q36-0544	.163	.171	1.375	.155	.160
A 9Q36-0548	.163	.171	1.500	.155	.160
A 9Q36-0616	.196	.205	.500	.185	.192
A 9Q36-0618	.196	.205	.562	.185	.192
A 9Q36-0620	.196	.205	.625	.185	.192
A 9Q36-0622	.196	.205	.688	.185	.192
A 9Q36-0624	.196	.205	.750	.185	.192
A 9Q36-0630	.196	.205	.938	.185	.192
A 9Q36-0632	.196	.205	1.000	.185	.192
A 9Q36-0636	.196	.205	1.125	.185	.192
A 9Q36-0640	.196	.205	1.250	.185	.192
A 9Q36-0648	.196	.205	1.500	.185	.192

* Made of 420 Stainless Steel - Rc 46-53.