

> **MATERIAL:**

Aluminum Alloy


PHONE: 516.328.3300 • FAX: 516.326.8827 • WWW.SDP-SI.COM

> **SPECIFICATION:**

Priced Per 25 Pieces



SDPSI • SDPSI • SDPSI

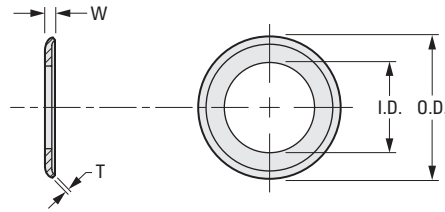

INCH COMPONENT

Catalog Number	Pulley Grooves Ref.	Inch		Metric		W Width ± .010 (± 0.25)	T Thickness
		I.D. ± .003	O.D. ± .016	I.D. ± 0.08	O.D. ± 0.4		
A 6A 5-010FA	10	.188	.425	4.77	10.8	.045 (1.14)	.025 (0.64)
A 6A 5-011FA	11	.214	.450	5.44	11.4		
A 6A 5-012FA	12	.218	.480	5.54	12.2		
A 6A 5-013FA	13	.244	.505	6.2	12.8		
A 6A 5-014FA	14	.270	.530	6.86	13.5		
A 6A 5-015FA	15	.296	.555	7.52	14.1		
A 6A 5-016FA	16	.322	.580	8.18	14.7		
A 6A 5-018FA	18	.374	.635	9.5	16.1		
A 6A 5-020FA	20	.426	.685	10.82	17.4	.052 (1.32)	.032 (0.81)
A 6A 5-021FA	21	.452	.710	11.48	18		
A 6A 5-022FA	22	.452	.740	11.48	18.8		
A 6A 5-024FA	24	.504	.790	12.8	20.1		
A 6A 5-025FA	25	.530	.815	13.46	20.7		
A 6A 5-026FA	26	.556	.840	14.12	21.3		
A 6A 5-028FA	28	.574	.895	14.58	22.7		
A 6A 5-030FA	30	.626	.945	15.9	24		
A 6A 5-032FA	32	.678	1.000	17.22	25.4		
A 6A 5-033FA	33	.704	1.025	17.88	26		
A 6A 5-034FA	34	.722	1.050	18.34	26.7		
A 6A 5-035FA	35	.748	1.080	19	27.4		
A 6A 5-036FA	36	.774	1.105	19.66	28.1		
A 6A 5-038FA	38	.826	1.155	20.98	29.3		
A 6A 5-040FA	40	.874	1.210	22.2	30.7		
A 6A 5-042FA	42	.926	1.260	23.52	32	.060 (1.52)	.040 (1.02)
A 6A 5-044FA	44	.978	1.315	24.84	33.4		
A 6A 5-045FA	45	1.044	1.340	26.52	34		
A 6A 5-048FA	48	1.058	1.420	26.87	36.1		
A 6A 5-050FA	50	1.110	1.470	28.19	37.3		
A 6A 5-054FA	54	1.200	1.575	30.48	40		
A 6A 5-060FA	60	1.356	1.730	34.44	43.9		

NOTE: Dimensions in () are mm.

- I
- R
- T
- 1
- 2**
- 3
- 4
- 5
- 6
- 7
- 8
- 9
- 10
- 11
- 12
- 13
- 14
- 15
- 16