



NEW

Ceramic Coated Aluminum

SOLID AND PREDRILLED SHAFTING

- 6105-T6 Aluminum Base Material • Rc 70 Ceramic Coated Finish
- Nonmagnetic and Vibration-Resistant
- Weld Splatter, Paints and Contaminants Will Not Stick




CERAMIC COATED ALUMINUM SOLID SHAFTING

Catalog Number	Nominal Shaft O.D.	Diameter Tolerance		Max. Length ft.	Weight Per Inch lbs.
		Min.	Max.		
BBSHAF-CC03-□□	3/16	.1863	.1871	12	.003
BBSHAF-CC04-□□	1/4	.2488	.2496		.005
BBSHAF-CC06-□□	3/8	.3738	.3746	12	.010
BBSHAF-CC08-□□	1/2	.4988	.4996		.019
BBSHAF-CC10-□□	5/8	.6238	.6246	12	.030
BBSHAF-CC12-□□	3/4	.7488	.7496		.043
BBSHAF-CC16-□□	1	.9988	.9996	12	.077
BBSHAF-CC20-□□	1-1/4	1.2488	1.2496		.120
BBSHAF-CC24-□□	1-1/2	1.4987	1.4995	12	.173
BBSHAF-CC32-□□	2	1.9985	1.9995		.308

Specify length in catalog number using inches.
 Example: for 1/2" shafting total length 36" long = **BBSHAF-CC08-36**.

Ends of cut-to-length shafting are not coated.
 Fully coated shafting is available on special request.

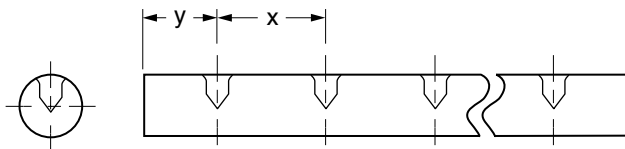

PREDRILLED & TAPPED SHAFTING

Catalog Number	Nominal Shaft O.D.	Diameter Tolerance		Hole Spacing		Thread	Max. Length ft.	Weight Per Inch lbs.
		Min.	Max.	x	y			
BBSHAF-CPDL08-□□	1/2	.4988	.4996	4	2	#6-32	12	.019
BBSHAF-CPDL10-□□	5/8	.6238	.6246	4	2	#8-32		.030
BBSHAF-CPDL12-□□	3/4	.7488	.7496	6	3	#10-32	12	.043
BBSHAF-CPDL16-□□	1	.9988	.9996	6	3	1/4-20		.077
BBSHAF-CPDL20-□□	1-1/4	1.2488	1.2496	6	3	5/16-18	12	.120
BBSHAF-CPDL24-□□	1-1/2	1.4987	1.4995	8	4	3/8-16		.173
BBSHAF-CPDL32-□□	2	1.9985	1.9995	8	4	1/2-13	.308	

Specify length in catalog number using inches.
 Example: for 1/2" shafting total length 36" long = **BBSHAF-CPDL08-36**.

For non-standard lengths, the "y" dimension will be held to one end. It may not be equal at both ends.

Ends of cut-to-length shafting are not coated.
 Fully coated shafting is available on special request.

Counterbore .063" from top.