





NEW



Frelon® Lined

FLANGE-MOUNTED SLEEVE BEARINGS

- Self-Lubricating
- Frelon® Liner
- 6061-T6 Aluminum Housing
- Self-Aligning

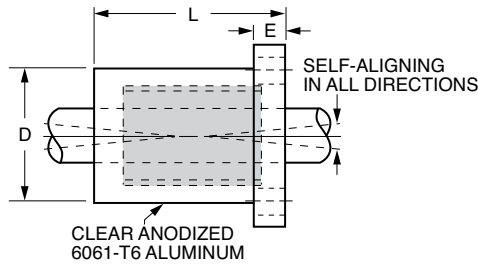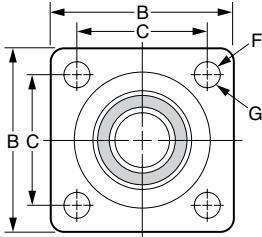

Catalog Number	Bearing Nominal Size	B Flange Square	C Hole Spacing	ØD Barrel	E Flange Length	F Bolt Size	G Hole Size	L Length Overall	Max. Static Load lbs.	Weight lbs.
BLAFMT-SFP08	1/2	1.63	1.25	1.25	.250	#8	.187	1.687	1950	.175
BLAFMT-SFP12	3/4	2.38	1.75	1.75	.375	#10	.219	2.067	2940	.463
BLAFMT-SFP16	1	2.75	2.125	2.25	.500	1/4	.281	2.812	3810	1.206

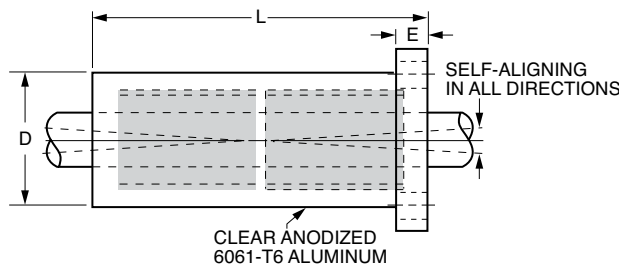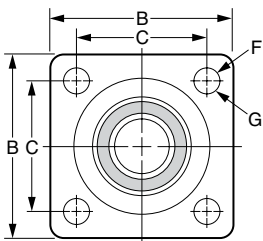

Catalog Number	Bearing Nominal Size	B Flange Square	C Hole Spacing	ØD Barrel	E Flange Length	F Bolt Size	G Hole Size	L Length Overall	Max. Static Load lbs.	Weight lbs.
BLAFMT-DFP08	1/2	1.63	1.25	1.25	.250	#8	.187	3.375	3900	.325
BLAFMT-DFP12	3/4	2.38	1.75	1.75	.375	#10	.219	4.188	5880	.825
BLAFMT-DFP16	1	2.75	2.125	2.25	.500	1/4	.281	5.625	7620	1.750

NOTE: All standard mounted units include a standard self-lubricating bearing **BLAABX-FLX..CP** series found on page 100.