


Outer Ring BEARING SPACERS

• 18-8 Stainless Steel

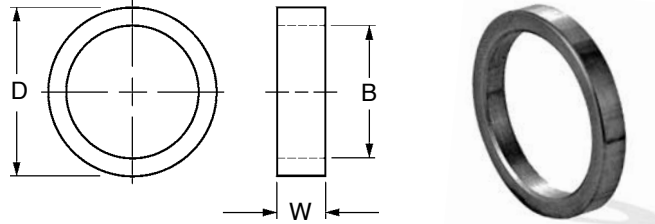

Catalog Number	B +.005 -.000	D ±.005	W
BHSOTR-088153003			.003
BHSOTR-088153005	.088	.153	.005 ±.001
BHSOTR-088153007			.007
BHSOTR-088153010	.088	.153	.010 ±.002
BHSOTR-088153020			.020
BHSOTR-123178003			.003
BHSOTR-123178005	.123	.178	.005 ±.001
BHSOTR-123178007			.007
BHSOTR-123178010	.123	.178	.010 ±.002
BHSOTR-123178020			.020
BHSOTR-167248003			.003
BHSOTR-167248005	.167	.248	.005 ±.001
BHSOTR-167248007			.007
BHSOTR-167248010	.167	.248	.010 ±.002
BHSOTR-167248020			.020
BHSOTR-206310003			.003
BHSOTR-206310005	.206	.310	.005 ±.001
BHSOTR-206310007			.007
BHSOTR-206310010	.206	.310	.010 ±.002
BHSOTR-206310020			.020
BHSOTR-253375003			.003
BHSOTR-253375005	.253	.373	.005 ±.001
BHSOTR-253375007			.007
BHSOTR-253375010	.253	.373	.010 ±.002
BHSOTR-253375020			.020
BHSOTR-253375032			.032
BHSOTR-253375062	.253	.373	.062 ±.003
BHSOTR-253375125			.125
BHSOTR-253375250			.250
BHSOTR-253375375	.253	.373	.375 ±.003
BHSOTR-253375500			.500
BHSOTR-378498003			.003
BHSOTR-378498005	.378	.498	.005 ±.001
BHSOTR-378498007			.007

Catalog Number	B +.005 -.000	D ±.005	W
BHSOTR-378498010			.010
BHSOTR-378498020	.378	.498	.020 ±.002
BHSOTR-378498032			.032
BHSOTR-378498062	.378	.498	.062 ±.003
BHSOTR-378498125			.125
BHSOTR-378498250			.250
BHSOTR-378198375	.378	.498	.375 ±.003
BHSOTR-378498500			.500
BHSOTR-503623003			.003
BHSOTR-503623005	.503	.623	.005 ±.001
BHSOTR-503623007			.007
BHSOTR-503603010	.503	.623	.010 ±.002
BHSOTR-503623020			.020
BHSOTR-503623032			.032
BHSOTR-503623062	.503	.623	.062 ±.003
BHSOTR-503623125			.125
BHSOTR-503623250			.250
BHSOTR-503623375	.503	.623	.375 ±.003
BHSOTR-503623500			.500
BHSOTR-562685016			.016 ±.002
BHSOTR-562685032	.562	.685	.032 ±.003
BHSOTR-562685062			.062 ±.003
BHSOTR-687873003			.003
BHSOTR-687873005	.687	.873	.005 ±.001
BHSOTR-687873007			.007
BHSOTR-687873010			.010
BHSOTR-687873016	.687	.873	.016 ±.002
BHSOTR-687873020			.020
BHSOTR-687873032			.032
BHSOTR-687873062	.687	.873	.062 ±.003
BHSOTR-687873125			.125
BHSOTR-687873250			.250
BHSOTR-687873375	.687	.873	.375 ±.003
BHSOTR-687873500			.500