




NEW

**Thin Section | Four-Point Contact
BALL BEARINGS**

- 52100 Chrome Steel
- Four-Point Contact Bearings
- Snap-Over Cage
- ABEC 1

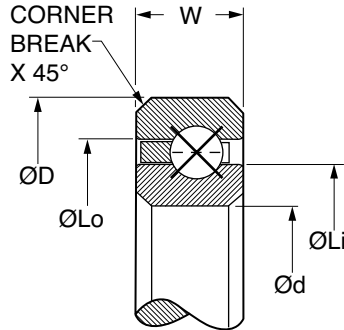

Catalog Number	d Bore	D O.D.	Pitch	W Width	Ball Complement		Internal Clearance	
					Ball Qty.	Ball Dia.	Min.	Max.
BBXFOR-KA035XPO	3.500	4.000	3.7500	.2500	45	1/8	.0016	.0026
BBXFOR-KB035XPO		4.125	3.8125	.3125	38	5/32		
BBXFOR-KA040XPO	4.000	4.500	4.2500	.2500	51	1/8	.0016	.0026
BBXFOR-KA040XPO		4.625	4.3125	.3125	43	5/32		
BBXFOR-KC040XPO	4.000	4.750	4.3750	.3750	35	3/16	.0016	.0026
BBXFOR-KD040XPO		5.000	4.500	.5000	27	1/4		
BBXFOR-KF040XPO	4.000	5.500	4.750	.7500	19	3/8	.0016	.0026
BBXFOR-KG040XPO		6.000	5.000	1.0000	15	1/2		
BBXFOR-KA042XPO	4.246	4.746	4.4962	.2500	54	1/8	.0016	.0026
BBXFOR-KB042XPO		4.871	4.5587	.3125	45	5/32		

Catalog Number	Lo Outer Race I.D.	Li Inner Race O.D.	Corner Break	Weight lbs.	Max. Radial rpm	Max. Axial rpm	Load Rating	
							Radial lbs.	Axial lbs.
BBXFOR-KA035XPO	3.813	3.687	.03	.18	1000	2857	450	1115
BBXFOR-KB035XPO	3.891	3.734	.05	.27		2900	635	1575
BBXFOR-KA040XPO	4.313	4.187	.03	.20	890	2500	490	1215
BBXFOR-KA040XPO	4.391	4.234	.05	.30	875	2600	700	1700
BBXFOR-KC040XPO	4.470	4.280	.05	.45	1000	2750	860	2130
BBXFOR-KD040XPO	4.626	4.374	.07	.78		1350	3350	
BBXFOR-KF040XPO	4.938	4.562	.09	1.90	1000	2650	2600	6500
BBXFOR-KG040XPO	5.251	4.749		3.60		2700	4450	11100
BBXFOR-KA042XPO	4.560	4.433	.03	.21	830	2360	510	1260
BBXFOR-KB042XPO	4.638	4.480	.05	.31	850	2400	705	1750

NOTE: Larger sizes available upon request. Stainless Steel available upon special request.

Minimum buy quantities may apply.

Continued on the next page